


SKINDICHT® BLK-GL-M

SKINDICHT® BLK-GL-M, -

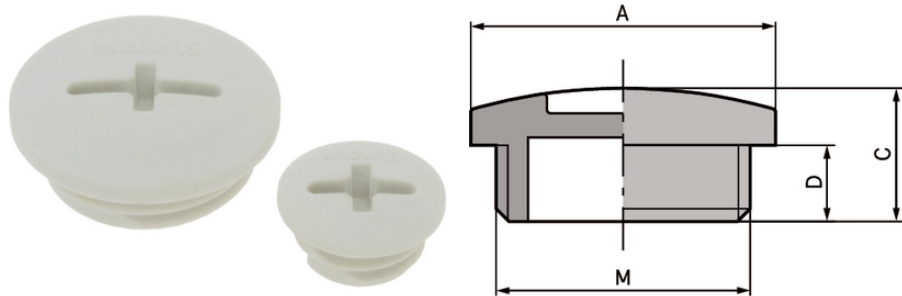

UL E79903

DIN EN 60423
DIN IEC 62444

SKINDICHT® BLK-GL-M

ETIM 5:

ETIM 5.0 Class-ID: EC000032

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000032

ETIM 6.0 Class :

:

UL

:

(RAL 7001)

(RAL 7035)

(RAL 9005)

:

O-Ring: NBR

가:

IP 54

IP 68 (with O-ring)

:

With O-ring: -20°C to +100°C

Without O-ring: -40°C to +100°C

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINDICHT® BLK-GL-M

	Article designation / size	, C mm	Thread length D mm	Ø (mm)	/ PU
SKINDICHT® BLK-GL-M -					
52006101	M 12 x 1,5	8.7	7	15.0	100
52006111	M 16 x 1,5	9.8	7	20.0	100
52006121	M 20 x 1,5	10.3	7	24.0	100
52006131	M 25 x 1,5	11.5	8	30.0	100
52006141	M 32 x 1,5	12.0	8	37.0	50
52006151	M 40 x 1,5	13.0	8	46.0	25
52006161	M 50 x 1,5	15.0	10	56.0	25
52006171	M 63 x 1,5	17.0	12	70.0	25
SKINDICHT® BLK-GL-M 가					
52006100	M 12 x 1,5	8.7	7	15.0	100
52006110	M 16 x 1,5	9.8	7	20.0	100
52006120	M 20 x 1,5	10.3	7	24.0	100
52006130	M 25 x 1,5	11.5	8	30.0	100
52006140	M 32 x 1,5	12.0	8	37.0	50
52006150	M 40 x 1,5	13.0	8	46.0	25
52006160	M 50 x 1,5	15.0	10	56.0	25
52006170	M 63 x 1,5	17.0	12	70.0	25
SKINDICHT® BLK-GL-M					
52006103	M 12 x 1,5	8.7	7	15.0	100
52006113	M 16 x 1,5	9.8	7	20.0	100
52006123	M 20 x 1,5	10.3	7	24.0	100
52006133	M 25 x 1,5	11.5	8	30.0	100
52006143	M 32 x 1,5	12.0	8	37.0	50
52006153	M 40 x 1,5	13.0	8	46.0	25
52006163	M 50 x 1,5	15.0	10	56.0	25
52006173	M 63 x 1,5	17.0	12	70.0	25
O- SKINDICHT® BLK-GL-M -					
52006109	M 12 x 1,5	8.7	7	15.0	100
52006119	M 16 x 1,5	9.8	7	20.0	100
52006129	M 20 x 1,5	10.3	7	24.0	100

SKINDICHT® BLK-GL-M

	Article designation / size	, C mm	Thread length D mm	Ø (mm)	/ PU
52006139	M 25 x 1,5	11.5	8	30.0	100
52006149	M 32 x 1,5	12.0	8	37.0	50
52006159	M 40 x 1,5	13.0	8	46.0	25
52006169	M 50 x 1,5	15.0	10	56.0	25
52006179	M 63 x 1,5	17.0	12	70.0	25
O- SKINDICHT® BLK-GL-M					
52006107	M 12 x 1,5	8.7	7	15.0	100
52006117	M 16 x 1,5	9.8	7	20.0	100
52006127	M 20 x 1,5	10.3	7	24.0	100
52006137	M 25 x 1,5	11.5	8	30.0	100
52006147	M 32 x 1,5	12.0	8	37.0	50
52006157	M 40 x 1,5	13.0	8	46.0	25
52006167	M 50 x 1,5	15.0	10	56.0	25
52006177	M 63 x 1,5	17.0	12	70.0	25
O- SKINDICHT® BLK-GL-M					
52006106	M 12 x 1,5	8.7	7	15.0	100
52006116	M 16 x 1,5	9.8	7	20.0	100
52006126	M 20 x 1,5	10.3	7	24.0	100
52006136	M 25 x 1,5	11.5	8	30.0	100
52006146	M 32 x 1,5	12.0	8	37.0	50
52006156	M 40 x 1,5	13.0	8	46.0	25
52006166	M 50 x 1,5	15.0	10	56.0	25
52006176	M 63 x 1,5	17.0	12	70.0	25