


SKINDICHT® BL

SKINDICHT® BL, PG

가

,

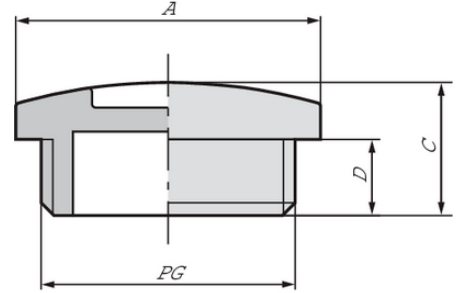

PG

ETIM 5:

ETIM 5.0 Class-ID: EC000032

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000032

ETIM 6.0 Class :

:

:

O- : NBR

가:

IP 54

IP 68 (with O-ring)

:

With O-ring: -20°C to +100°C

Without O-ring: -60°C to +200°C

(22.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINDICHT® BL

가 VAT 가 가 .

(22.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINDICHT® BL

	Article designation / size	/ PU
SKINDICHT® BL		
52002680	PG 7	100
52003390	PG 9	100
52003400	PG 11	100
52003410	PG 13,5	100
52003420	PG 16	100
52003430	PG 21	50
52003440	PG 29	50
52003450	PG 36	25
52003460	PG 42	10
52002790	PG 48	10
SKINDICHT® BL, O-		
54001610	PG 7	100
54000071	PG 9	100
54000040	PG 11	100
54001630	PG 13,5	100
54001640	PG 16	100
54001660	PG 21	50
54001620	PG 29	50
54001650	PG 36	25
54001670	PG 42	10
54001680	PG 48	10