


SKINDICHT® STK

SKINDICHT® STK, PVC ,

가

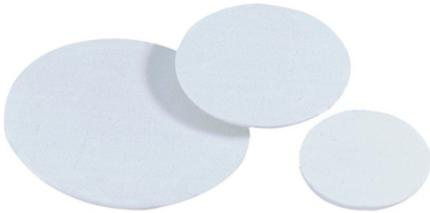

가

This dust protector can be placed under the cap nut of the cable gland

가 () 가 ,

ETIM 5:

ETIM 5.0 Class-ID: EC000032

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000032

ETIM 6.0 Class :

:

:

:

PVC

-20°C +80°C

가 VAT 가 가 .

(25.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINDICHT® STK

	Article designation / size	(thread) , PG	SKINDICHT® SVRN-M, SHZ-M, SKZ-M, SVR-M, SVRE-M, SHVE-M, SHV-M	/ PU
SKINDICHT® STK				
52020818	STK 7	7	M 12	500
52020820	STK 9	9	M 16	500
52020830	STK 11	11	M 20/11	250
52020840	STK 13,5	13.5	M 20/13,5	250
52020850	STK 16	16	M 20/16	250
52020860	STK 21	21	M 25	250
52020870	STK 29	29	M 32	100
52020880	STK 36	36	M 40	100
52020890	STK 42	42	M 50	50
52020900	STK 48	48	M 63	50