




SKINDICHT® CN

SKINDICHT® CN, ,

PG

, -40°C

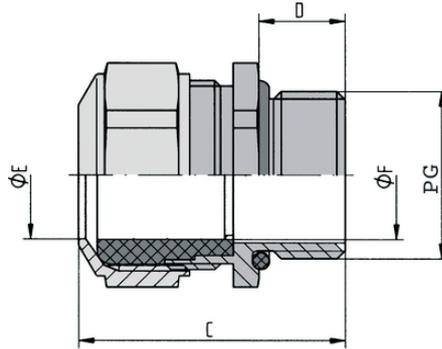

FKM

(24.04.2024)



SKINDICHT® CN

PG

SKINDICHT® SM CrNi

ETIM 6:

:

:

:

가:

:

ETIM 6.0 Class-ID: EC000441

ETIM 6.0 Class :

T21

TPE

: DIN

no. 1.4305

: FPM

O- : FPM

IP 68 - 5 bar

-40 ~ 200°C

가 VAT

가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINDICHT® CN

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	/ PU
SKINDICHT® CN						
52032520	PG 9	6 - 10	18	28.0	10	5
52032525	PG 11	5 - 12	22	32.0	10	5
52032540	PG 13,5	8 - 15	24	34.0	10	5
52032550	PG 16	8 - 15	24	34.0	10	5
52032560	PG 21	12.5 - 20.5	30	42.0	12	5
52032570	PG 29	19 - 27.5	41	53.0	12	5

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16