


# SKINDICHT® MINI FKM

SKINDICHT® MINI, 가

+200°C

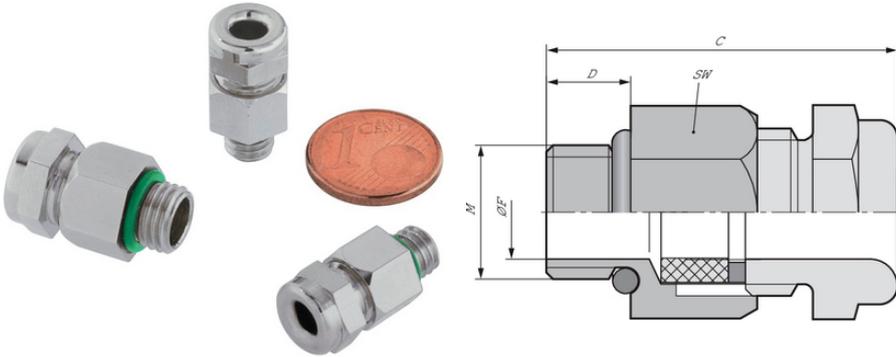

Lapp



가

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# SKINDICHT® MINI FKM

ETIM 5:	ETIM 5.0 Class-ID: EC000441
	ETIM 5.0 :
ETIM 6:	ETIM 6.0 Class-ID: EC000441
	ETIM 6.0 Class :
:	
	M 6 x 1 1.5 Nm
	M 8 x 1 3.0 Nm
:	:
	: FKM
가:	IP 66
	IP 68 - 5 bar
:	-20°C +200°C

가 VAT 가 가 .

(23.04.2024)



# SKINDICHT® MINI FKM

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	F (mm)	/ PU
52001889	M 6 x 1	2 - 3	9	19.7	5	3.0	50
52001887	M 8 x 1	3.5 - 5	11	20.5	5	5.5	50
52001894	M 10 x 1	5.5 - 7	14	22.3	5	7.4	50

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16