


**SKINDICHT® SR-SV-M**

SKINDICHT® SR-SV-M, , , ,

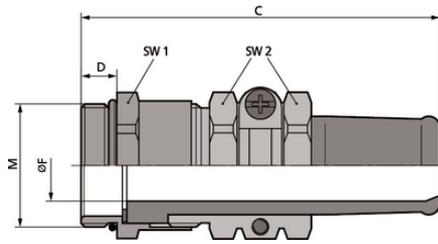

VDE 0700-1

FKM (anti-kink)가

FKM +165

DIN EN 60423

DIN IEC 62444

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# SKINDICHT® SR-SV-M

: SKINDICHT® SM-M

EMC

:

SR-SV-M 20/11/7

20 =

11 = PG

7 =

ETIM 5:

ETIM 5.0 Class-ID: EC000441

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000441

ETIM 6.0 Class :

:

T21

:

가

:

:

O- : FKM

: FKM

가:

IP 65

:

-20°C to +165°C

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# SKINDICHT® SR-SV-M

	Article designation / size	Clamping range ØF mm	. (mm)	(thread) PG	SW1/SW2 mm	, C mm	Thread length D mm	F (mm)	/ PU
SKINDICHT® SR-SV-M									
52105820	M 20 x 1,5	5.5 - 7.0	28	11	22 / 20	56.0	6	7.0	25
52105830	M 20 x 1,5	7.5 - 9.0	28	11	22 / 20	56.0	6	9.0	25
52105840	M 20 x 1,5	7.5 - 9.0	32	13.5	22 / 22	61.5	6	9.0	25
52105850	M 20 x 1,5	8.5 - 11.0	32	13.5	22 / 22	61.5	6	11.0	25
52105860	M 20 x 1,5	10.5 - 13.0	32	13.5	22 / 22	61.5	6	13.0	25
52105870	M 20 x 1,5	11.0 - 13.0	35	16	24 / 24	66.5	6	13.0	10
52105880	M 20 x 1,5	12.0 - 15.0	35	16	24 / 24	66.5	6	15.0	10
52105890	M 25 x 1,5	13.5 - 15.0	40	21	30 / 30	79.0	7	15.0	10
52105900	M 25 x 1,5	15.5 - 17.0	46	21	30 / 30	79.0	7	17.0	10
52105910	M 25 x 1,5	16.5 - 19.0	46	21	30 / 30	79.0	7	19.0	10

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16