


# SKINTOP® CUBE

SKINTOP® CUBE, , 가

가

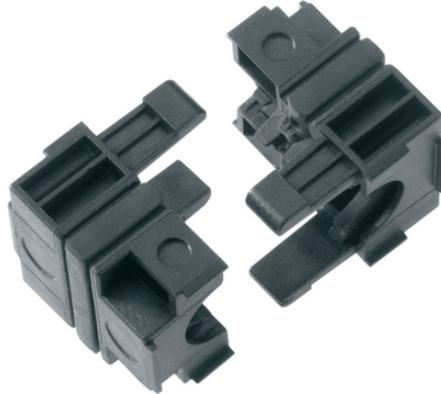

**CE UK CA**



(24.04.2024)

# SKINTOP® CUBE

UL 50, UL 50E, CSA C22.2  
 UL 508A( : )  
 UL File No. E349737

SKINTOP® CUBE      SKINTOP® CUBE FRAME      SKINTOP® CUBE MODULE

가 ( )  
 16- (36 x 86 mm)  
 24- (36 x 112 mm)

SKINTOP® CUBE MODULE 20x20 BLIND      1-3 mm      가

ETIM 5:      ETIM 5.0 Class-ID: EC000240  
 ETIM 5.0 :  
 ETIM 6:      ETIM 6.0 Class-ID: EC000240  
 ETIM 6.0 Class :  
 :      UL File No. E349737  
 Fire behaviour according to UL94 HB (Frame) and V-0  
 (Modules)

:      The installation dimensions and possible module combinations  
 can be found in appendix T21

:      : -  
 : CR  
 :  
 : LSE 2

가:      IP 64  
 :      Dynamisch: -20°C bis +80°C  
 Statisch: -40°C bis +80°C

가    VAT    가    가 .

(24.04.2024)



# SKINTOP® CUBE

	Article designation / size	Ø F mm	.	/ PU
SKINTOP® CUBE				
52220000	SKINTOP® CUBE FRAME 16	-	8	1
52220001	SKINTOP® CUBE FRAME 24	-	10	1
SKINTOP® CUBE				
52220004	SKINTOP® CUBE MODULE 20x20 BLIND	1.0 - 3.0	-	5
52220002	SKINTOP® CUBE MODULE 20x20 SMALL	4.0 - 6.0	-	5
52220003	SKINTOP® CUBE MODULE 20x20 LARGE	6.0 - 9.0	-	5
52220040	SKINTOP® CUBE MODULE 20x20 AS-I BUS	-	-	5
52220005	SKINTOP® CUBE MODULE 40x40 SMALL	9.0 - 12.0	-	5
52220006	SKINTOP® CUBE MODULE 40x40 LARGE	12.0 - 16.0	-	5
52220007	SKINTOP® CUBE MODULE 40x40 BLIND	-	-	5

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16

## SKINTOP® CUBE



(24.04.2024)