


SKINTOP® MS-M BRUSH

SKINTOP® MS-M BRUSH, 가 , , 360° ,

NEW: Now also available in size M20x1.5

가 가 75 x 1.5 110 x 2

SKINTOP® MS-M

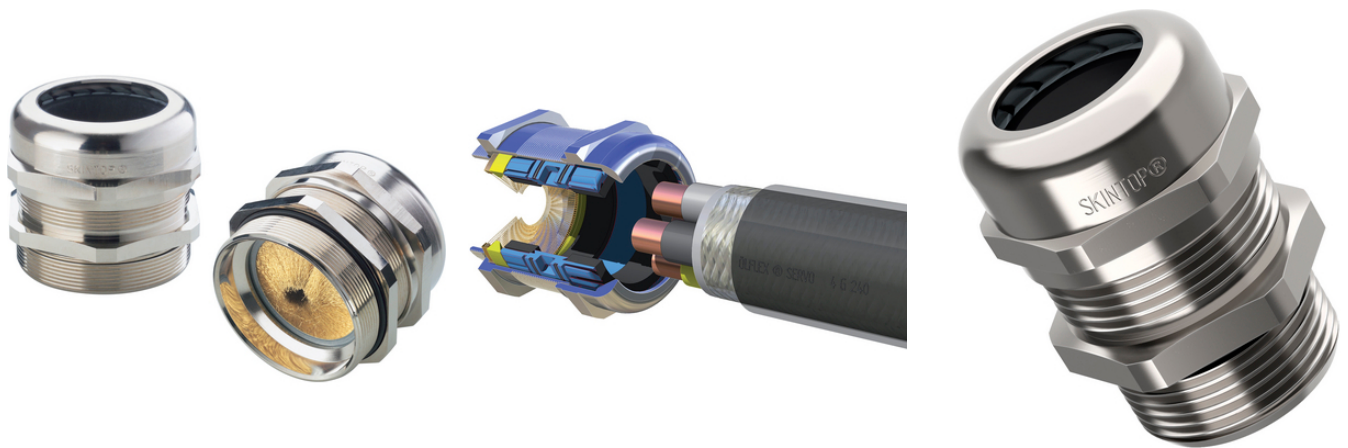

360°

가

EMC

-

(25.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINTOP® MS-M BRUSH

UL E79903

DIN EN 60423
DIN IEC 62444

SKINDICHT® SM-PE-M

ETIM 5:

ETIM 5.0 Class-ID: EC000441
ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000441
ETIM 6.0 Class :

:

T21

:

:

:

:

UL 94

EMC brush :

:

O :

가:

IP 68 - 10 bar (M12 - M110)

IP 69 (M12 - M63)

NEMA Type 1, 4x, 6, 12

:

Dynamic: -25°C up to +100°C
: -40°C +100°C

가 VAT 가 가 .

(25.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>


data sheet

PN 0456 / 02_03.16

SKINTOP® MS-M BRUSH

	Article designation / size	Ø (mm), from - to	(mm) Ø	SW (mm)	Thread length D mm	/ PU
SKINTOP® MS-M BRUSH						
53112507	M 20 x 1,5	7.0 - 13.0	3	24	8	25
53112676	M 25 x 1,5	9.0 - 17.0	6	29	8	10
53112677	M 32 x 1,5	11.0 - 21.0	8	36	9	5
53112678	M 40 x 1,5	19.0 - 28.0	10	45	9	5
53112679	M 50 x 1,5	27.0 - 35.0	14	54	10	5
53112680	M 63 x 1,5	34.0 - 45.0	20	67	15	1
53112681	M 63 x 1,5 plus	44.0 - 55.0	25	75	15	1
53112501	M 75 x 1,5	53.0 - 63.0	25	95	15	1
53112500	M 75 x 1,5 plus	58.0 - 68.0	25	95	15	1
53112503	M 90 x 2	66.0 - 78.0	40	115	20	1
53112505	M 110 x 2	76.0 - 88.0	50	135	25	1
53112504	M 110 x 2 plus	86.0 - 98.0	50	135	25	1
SKINTOP® MS-M BRUSH XL						
53112527	M 20 x 1,5	7.0 - 13.0	3	24	12	25
53113727	M 25 x 1,5	9.0 - 17.0	6	29	12	10
53113728	M 32 x 1,5	11.0 - 21.0	8	36	15	5
53113729	M 40 x 1,5	19.0 - 28.0	10	45	15	5
53112673	M 50 x 1,5	27.0 - 35.0	14	54	15	5

SKINTOP® MS-M BRUSH

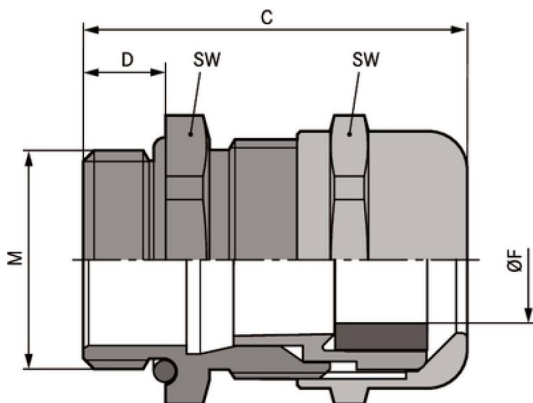

(25.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16