

# SKINTOP® MS-SC-M

SKINTOP® MS-SC-M,

EMC ,

Also available as lead-free version - the lead-free articles end on LF after the article number



- , EMC /

가 EMC

EMC



# SKINTOP® MS-SC-M

UL E79903

DIN EN 60423  
DIN IEC 62444

SKINDICHT® SM-PE-M

ETIM 5:	ETIM 5.0 Class-ID: EC000441
	ETIM 5.0 :
ETIM 6:	ETIM 6.0 Class-ID: EC000441
	ETIM 6.0 Class :
:	T21
:	V2A 가
:	:
	: CR
가:	O- : NBP
	IP 68 - 10 bar
	IP 69
	NEMA Type 1, 4x, 6, 12
:	Dynamic: -25°C up to +100°C
	: -40°C ~ +100°C

가 VAT 가 가 .

(24.04.2024)



SKINTOP® MS-SC-M

	Article designation / size	Ø (mm), from - to	(mm) Ø	SW (mm)	Thread length D mm	/ PU
SKINTOP® MS-SC-M						
53112610	M 12 x 1,5	3.5 - 7.0	1	16	6.5	50
53112620	M 16 x 1,5	4.5 - 10.0	4	20	7	50
53112630	M 20 x 1,5	7.0 - 13.0	5	24	8	25
53112640	M 25 x 1,5	9.0 - 17.0	7.5	29	8	25
53112650	M 32 x 1,5	11.0 - 21.0	9	36	9	25
53112660	M 40 x 1,5	19.0 - 28.0	15	45	9	10
53112670	M 50 x 1,5	27.0 - 35.0	21	54	10	5
SKINTOP® MS-SC-M-XL						
53112625	M 16 x 1,5	4.5 - 10.0	4	20	12	50
53112635	M 20 x 1,5	7.0 - 13.0	5	24	12	25
53112645	M 25 x 1,5	9.0 - 17.0	7.5	29	12	25
53112655	M 32 x 1,5	11.0 - 21.0	9	36	15	25
53112665	M 40 x 1,5	19.0 - 28.0	15	45	15	10
53112675	M 50 x 1,5	27.0 - 35.0	21	54	15	5
53112610LF	M 12 x 1,5	3.5 - 7.0	1	16	6.5	50
53112620LF	M 16 x 1,5	4.5 - 10.0	4	20	7	50
53112630LF	M 20 x 1,5	7.0 - 13.0	5	24	8	25
53112640LF	M 25 x 1,5	9.0 - 17.0	7.5	29	8	25
53112650LF	M 32 x 1,5	11.0 - 21.0	9	36	9	25
53112660LF	M 40 x 1,5	19.0 - 28.0	15	45	9	10
53112670LF	M 50 x 1,5	27.0 - 35.0	21	54	10	5

(24.04.2024)



©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03\_16

# SKINTOP® MS-SC-M

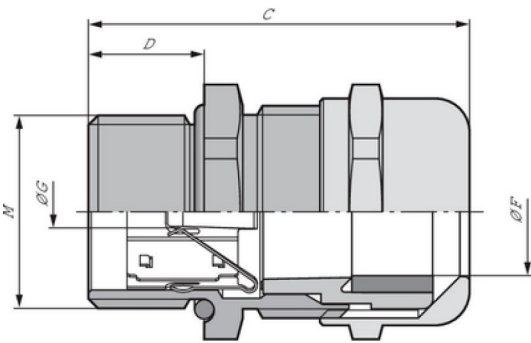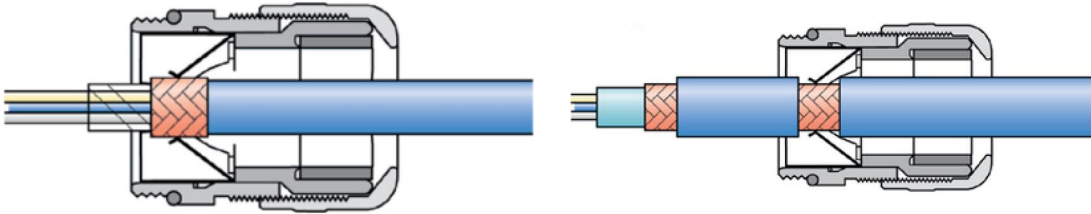

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16