


SKINTOP® BS-M METAL / SKINTOP® BSR-M METAL

Brass cable gland with bending protection spiral for use on moving machine parts.

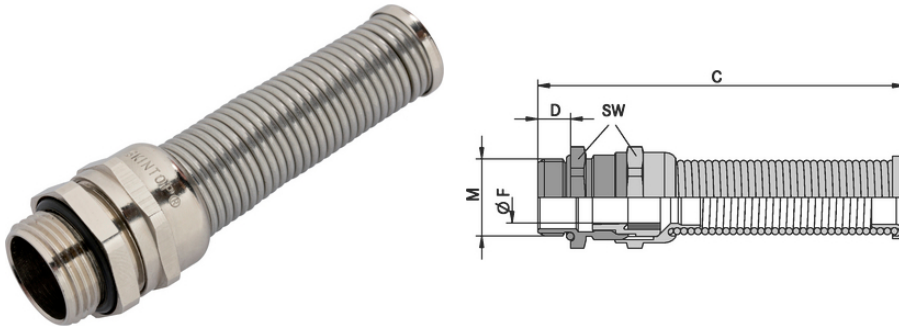

Bending protection spiral prevents excessive bending as well as kinking of the connected cable.
 Special design of the stainless steel spiral allows high number of bending cycles.
 Large, variable clamping range for different cable outer diameters.
 Best possible sealing by O-ring and sealing ring enables protection class IP 68 (10 bar) and IP 69.

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINTOP® BS-M METAL / SKINTOP® BSR-M METAL

Especially on moving machine parts.
Withstands high mechanical loads.
Suitable for outdoor use.

DIN EN 60423

DIN IEC 62444

Variant "R" with reduction sealing insert for sealing smaller diameter pipes.

ETIM 5:

ETIM 5.0 Class-ID: EC000441

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000441

ETIM 6.0 Class :

:

T21

:

:

:

: CR

O- : NBP

가:

IP 68 - 10 bar

IP 69

:

Dynamic: -25°C up to +100°C

Fixed: -30°C up to +100°C

가 VAT

가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINTOP® BS-M METAL / SKINTOP® BSR-M METAL

	Article designation / size	Ø F mm	Thread length D mm	SW (mm)	, C mm	/ PU
SKINTOP® BS-M METAL						
53806759	M 12 x 1,5	3.5 - 7.0	6.5	16	65.0	25
53806760	M 16 x 1,5	4.5 - 10.0	7	20	79.0	25
53806761	M 20 x 1,5	7 - 13.0	8	24	95.0	25
53806762	M 25 x 1,5	9 - 17.0	8	29	109.0	25
SKINTOP® BSR-M METAL						
53806769	M 12 x 1,5	2 - 5.0	6.5	16	65.0	25
53806770	M 16 x 1,5	2 - 7.0	7	20	79.0	25
53806771	M 20 x 1,5	5 - 10.0	8	24	95.0	25
53806772	M 25 x 1,5	6 - 13.0	8	29	109.0	25