

SKINTOP® MS-M-XL


SKINTOP® MS-M-XL,

가

,

Mit IP69 !

가

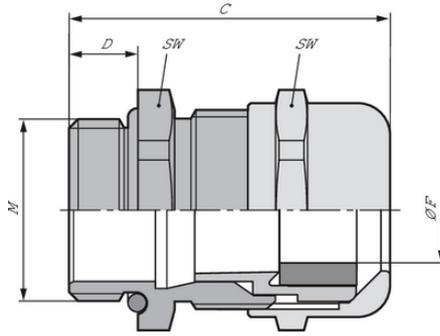

(23.04.2024)



SKINTOP® MS-M-XL

With long connection thread for applications involving a thicker wall

UL E79903

DIN EN 60423
DIN IEC 62444

ETIM 5:	ETIM 5.0 Class-ID: EC000441
	ETIM 5.0 :
ETIM 6:	ETIM 6.0 Class-ID: EC000441
	ETIM 6.0 Class :
:	T21
:	:
	:
	: CR
가:	O- : NBP
	IP 68 - 10 bar
	IP 69
	NEMA Type 1, 4x, 6, 12
:	Dynamic: -25°C up to +100°C
	: -40°C +100°C

가 VAT 가 가 .

(23.04.2024)



SKINTOP® MS-M-XL

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	/ PU
SKINTOP® MS-M-XL						
53112005	M 12 x 1,5	3.5 - 7.0	16	32.0	12	100
53112015	M 16 x 1,5	4.5 - 10.0	20	38.0	12	50
53112025	M 20 x 1,5	7 - 13.0	24	41.0	12	50
53112035	M 25 x 1,5	9 - 17.0	29	42.5	12	25
53112045	M 32 x 1,5	11 - 21.0	36	51.5	15	25
53112055	M 40 x 1,5	19 - 28.0	45	54.5	15	10
53112065	M 50 x 1,5	27 - 35.0	54	60.5	15	5

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16