


SKINTOP® HYGIENIC SC NPT

SKINTOP® HYGIENIC / SKINTOP® HYGIENIC-R,

가

NSF/ANSI 169 : "for use in food zone non contact"

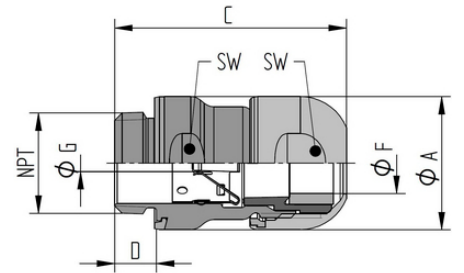

- , EMC

EMC

가

(24.04.2024)



SKINTOP® HYGIENIC SC NPT

EMC

EHEDG (TYPE EL Class I AUX)

()

ECOLAB®

FDA 21 CFR 177.2600

DIN EN 1672-2

DIN EN ISO 14159

Security of machinery – Hygienic requirements for the design of machinery

NSF/ANSI 169

ASME B1.20.1 - 2013

NPT

:

T21

:

:

- V4A (1.4404/316L)

:

:

가:

IP 68 - 10 bar

IP 69

NEMA Type 1, 2, 4x, 6, 12

:

-20°C +100°C

가 VAT

가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINTOP® HYGIENIC SC NPT

	Article designation / size	Ø F mm	Thread length D mm	SW (mm)	, C mm	/ PU
54114300	NPT 1/4"	4 - 6	7.2	16	39.5	5
54114310	NPT 3/8"	6.5 - 9	7.8	20	42.5	5
54114320	NPT 1/2"	9 - 12	8.4	24	47.0	5
54114330	NPT 3/4"	11.5 - 15.5	8.8	29	50.0	5

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16