


SKINTOP® INOX NPT

SKINTOP® INOX / SKINTOP® INOX-R,

가

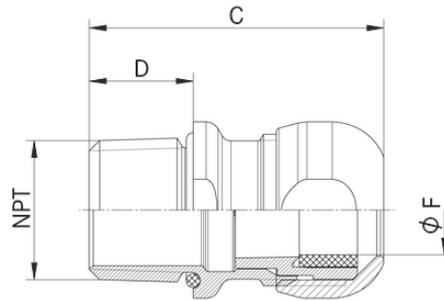

(24.04.2024)

SKINTOP® INOX NPT

(,)

ECOLAB®

DIN EN 1672-2

DIN EN ISO 14159

Security of machinery – Hygienic requirements for the design of machinery
NSF/ANSI 169

ASME B1.20.1 - 2013 NPT

ETIM 5:	ETIM 5.0 Class-ID: EC000441 ETIM 5.0 :
ETIM 6:	ETIM 6.0 Class-ID: EC000441 ETIM 6.0 Class :
:	Body: stainless steel V4A (1.4404 / 316L) Insert: polyamide Sealing: silicone O-Ring: silicone
가:	IP 68 - 5 bar IP 69 NEMA Type 1, 2, 4x, 6, 12
:	-40°C ~ +100°C

가 VAT 가 가 .

(24.04.2024)



SKINTOP® INOX NPT

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	/ PU
SKINTOP® INOX NPT						
53806778	NPT 1/4"	4 - 7	16	37.8	15	5
53806779	NPT 3/8"	6 - 10	20	40.4	15	5
53806780	NPT 1/2"	7 - 13	24	42.5	15	5
53806781	NPT 3/4"	9 - 17	29	46.2	15	5
53806782	NPT 1"	11 - 21	36	50.6	15	5
53806783	NPT 1 1/4"	19 - 28	45	59.2	17	5
53806784	NPT 1 1/2"	27 - 35	54	63.2	17	5
SKINTOP® INOX-R NPT						
53806796	NPT 1/4"	3 - 5	16	37.8	15	5
53806797	NPT 3/8"	5 - 7	20	40.4	15	5
53806798	NPT 1/2"	6 - 10	24	42.5	15	5
53806799	NPT 3/4"	7 - 13	29	46.2	15	5
53806800	NPT 1"	8 - 15	36	50.6	15	5
53806801	NPT 1 1/4"	15 - 23	45	59.2	17	5
53806802	NPT 1 1/2"	22 - 29	54	63.2	17	5

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03_16