

# SKINTOP® BS-M

SKINTOP® BS-M,

(anti-kink)



Lapp



VDE 0700-1

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# SKINTOP® BS-M

UL E79903

DIN EN 60423  
DIN IEC 62444

SKINTOP® BS M ISO , 가 SKINTOP® BSR 가  
(thread) , , DNV

ETIM 5: ETIM 5.0 Class-ID: EC000441  
ETIM 5.0 :

ETIM 6: ETIM 6.0 Class-ID: EC000441  
ETIM 6.0 Class :

: T21

:  
:  
:  
(RAL 7001)  
(RAL 7035)  
(RAL 9005), UV-

:  
:  
: CR

가: IP 68 - 5 bar  
NEMA Type 1, 12


: -20°C +100°C

가 VAT 가 가 .

(23.04.2024)

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	/ PU
SKINTOP® BS-M						
53111600	M 12 x 1,5	3.5 - 7	15	64.0	8	100
53111610	M 16 x 1,5	4 - 10	19	86.0	8	100
53111620	M 20 x 1,5	6 - 13	25	101.0	9	50
53111630	M 25 x 1,5	8 - 17	30	125.0	10	25
53111640	M 32 x 1,5	9 - 21	36	149.0	10	25
SKINTOP® BS-M						
53111700	M 12 x 1,5	3.5 - 7	15	64.0	8	100
53111710	M 16 x 1,5	4 - 10	19	86.0	8	100
53111720	M 20 x 1,5	6 - 13	25	101.0	9	50
53111730	M 25 x 1,5	8 - 17	30	125.0	10	25
53111740	M 32 x 1,5	9 - 21	36	149.0	10	25
SKINTOP® BS-M						
53111800	M 12 x 1,5	3.5 - 7	15	64.0	8	100
53111810	M 16 x 1,5	4 - 10	19	86.0	8	100
53111820	M 20 x 1,5	6 - 13	25	101.0	9	50
53111830	M 25 x 1,5	8 - 17	30	125.0	10	25
53111840	M 32 x 1,5	9 - 21	36	149.0	10	25
SKINTOP® BS M ISO - ( (thread) )						
53017610	M 16 x 1,5 ISO	3.5 - 8	19	77.5	12	100
53017630	M 20 x 1,5 ISO	5 - 12	24	102.0	13	50
53017640	M 25 x 1,5 ISO	9 - 14	27	114.5	13	50
SKINTOP® BS M ISO ( (thread) )						
53017810	M 16 x 1,5 ISO	3.5 - 8	19	77.5	12	100
53017830	M 20 x 1,5 ISO	5 - 12	24	102.0	13	50
53017840	M 25 x 1,5 ISO	9 - 14	27	114.5	13	50

# SKINTOP® BS-M

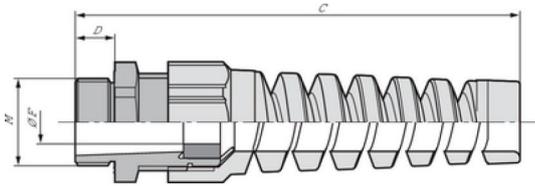

(23.04.2024)

©2024 Lapp Group - all rights reserved.  
<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16