

SKINTOP® CLICK BS

SKINTOP® CLICK BS,

CLICK

가

가



CLICK

70%

가

(24.04.2024)



SKINTOP® CLICK BS

VDE 0700-1

UL E79903

ETIM 5:	ETIM 5.0 Class-ID: EC000441
	ETIM 5.0 :
ETIM 6:	ETIM 6.0 Class-ID: EC000441
	ETIM 6.0 Class :
:	(RAL 7001)
	(RAL 7035)
	(RAL 9005), UV-
:	:
	:
가:	IP 68 - 4 bar (M12)
	IP 68 - 5 bar (M16 - M25)
	IP 68 - 1 bar (M32)
:	-20°C +100°C

가 VAT 가 가 .

(24.04.2024)



SKINTOP® CLICK BS

	Article designation / size	Ø F mm	M (mm)	SW1/SW2 mm	, C mm	Thread length D mm	, S (mm)	/ PU
SKINTOP® CLICK BS								
53112932	CLICK BS 12	3.5 - 7	12.3 (-0.2)	18.0 / 15.0	74.0	8	1.0 - 4.0	50
53112888	CLICK BS 16	5 - 9	16.3 (-0.2)	22.0 / 19.0	94.0	8	1.0 - 4.0	50
53112889	CLICK BS 20	7 - 13	20.3 (-0.2)	27.0 / 25.0	108.0	8	1.0 - 4.0	25
53112890	CLICK BS 25	9 - 17	25.3 (-0.2)	32.0 / 30.0	127.0	8	1.0 - 4.0	25
53112933	CLICK BS 32	11 - 20	32.3 (-0.2)	40.0 / 36.0	156.0	8	1.0 - 4.0	25
SKINTOP® CLICK BS								
53112934	CLICK BS 12	3.5 - 7	12.3 (-0.2)	18.0 / 15.0	74.0	8	1.0 - 4.0	50
53112906	CLICK BS 16	5 - 9	16.3 (-0.2)	22.0 / 25.0	94.0	8	1.0 - 4.0	50
53112907	CLICK BS 20	7 - 13	20.3 (-0.2)	27.0 / 25.0	108.0	8	1.0 - 4.0	25
53112908	CLICK BS 25	9 - 17	25.3 (-0.2)	32.0 / 30.0	127.0	8	1.0 - 4.0	25
53112935	CLICK BS 32	11 - 20	32.3 (-0.2)	40.0 / 36.0	156.0	8	1.0 - 4.0	25
SKINTOP® CLICK BS								
53112936	CLICK BS 12	3.5 - 7	12.3 (-0.2)	18.0 / 15.0	74.0	8	1.0 - 4.0	50
53112909	CLICK BS 16	5 - 9	16.3 (-0.2)	22.0 / 19.0	94.0	8	1.0 - 4.0	50
53112911	CLICK BS 20	7 - 13	20.3 (-0.2)	27.0 / 25.0	108.0	8	1.0 - 4.0	25
53112912	CLICK BS 25	9 - 17	25.3 (-0.2)	32.0 / 30.0	127.0	8	1.0 - 4.0	25
53112937	CLICK BS 32	11 - 20	32.3 (-0.2)	40.0 / 36.0	156.0	8	1.0 - 4.0	25

(24.04.2024)


©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINTOP® CLICK BS

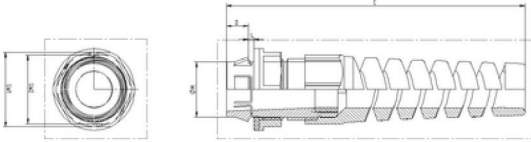

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16