

SKINTOP® CLICK

SKINTOP® CLICK,

CLICK

가

가

In practical box available in the web catalogue



CLICK 가

70%

(21.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINTOP® CLICK

UL E79903

ETIM 5:

ETIM 5.0 Class-ID: EC000441

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000441

ETIM 6.0 Class :

:

(RAL 7001)

(RAL 7035)

(RAL 9005), UV-

:

:

:

가:

IP 68 - 4 bar (M12)

IP 68 - 5 bar (M16 - M25)

IP 68 - 1 bar (M32)

:

: -20°C ~ +100°C

: -40°C +100°C

가 VAT 가 가 .

(21.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>


data sheet

PN 0456 / 02_03.16

SKINTOP® CLICK

	Article designation / size	Ø F mm	M (mm)	SW1/SW2 mm	, C mm	Thread length D mm	, S (mm)	/ PU
SKINTOP® CLICK								
53112692	CLICK 12	4.5 - 7.0	12.3 (-0.2)	15.0 / 18.0	40.0	8	1.0 - 4.0	50
53112686	CLICK 16	5.0 - 9.0	16.3 (-0.2)	19.0 / 22.0	42.0	8	1.0 - 4.0	50
53112687	CLICK 20	7.0 - 13.0	20.3 (-0.2)	25.0 / 27.0	45.0	8	1.0 - 4.0	25
53112688	CLICK 25	9.0 - 17.0	25.3 (-0.2)	30.0 / 32.0	48.0	8	1.0 - 4.0	25
53112694	CLICK 32	11.0 - 20.0	32.3 (-0.2)	36.0 / 40.0	56.0	8	1.0 - 4.0	25
SKINTOP® CLICK								
53112921	CLICK 12	4.5 - 7.0	12.3 (-0.2)	15.0 / 18.0	40.0	8	1.0 - 4.0	50
53112876	CLICK 16	5.0 - 9.0	16.3 (-0.2)	19.0 / 22.0	42.0	8	1.0 - 4.0	50
53112877	CLICK 20	7.0 - 13.0	20.3 (-0.2)	25.0 / 27.0	45.0	8	1.0 - 4.0	25
53112878	CLICK 25	9.0 - 17.0	25.3 (-0.2)	30.0 / 32.0	48.0	8	1.0 - 4.0	25
53112922	CLICK 32	11.0 - 20.0	32.3 (-0.2)	36.0 / 40.0	56.0	8	1.0 - 4.0	25
SKINTOP® CLICK								
53112923	CLICK 12	4.5 - 7.0	12.3 (-0.2)	15.0 / 18.0	40.0	8	1.0 - 4.0	50
53112882	CLICK 16	5.0 - 9.0	16.3 (-0.2)	19.0 / 22.0	42.0	8	1.0 - 4.0	50
53112883	CLICK 20	7.0 - 13.0	20.3 (-0.2)	25.0 / 27.0	45.0	8	1.0 - 4.0	25
53112884	CLICK 25	9.0 - 17.0	25.3 (-0.2)	30.0 / 32.0	48.0	8	1.0 - 4.0	25
53112924	CLICK 32	11.0 - 20.0	32.3 (-0.2)	36.0 / 40.0	56.0	8	1.0 - 4.0	25

SKINTOP® CLICK

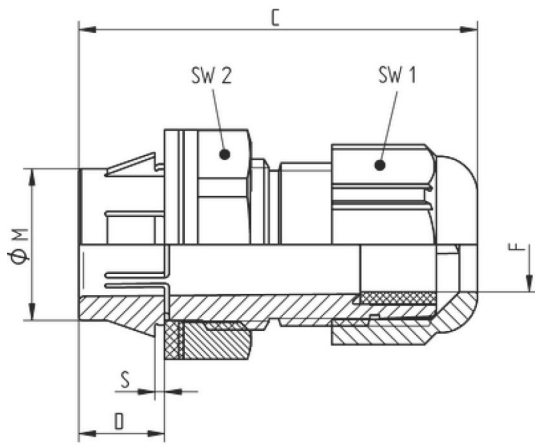

(21.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16