


SKINTOP® FIBER

SKINTOP® FIBER, cable gland for fiber optic cables, strain relief and sealing

Enables a good fixation and sealing without impairing the transmission performance

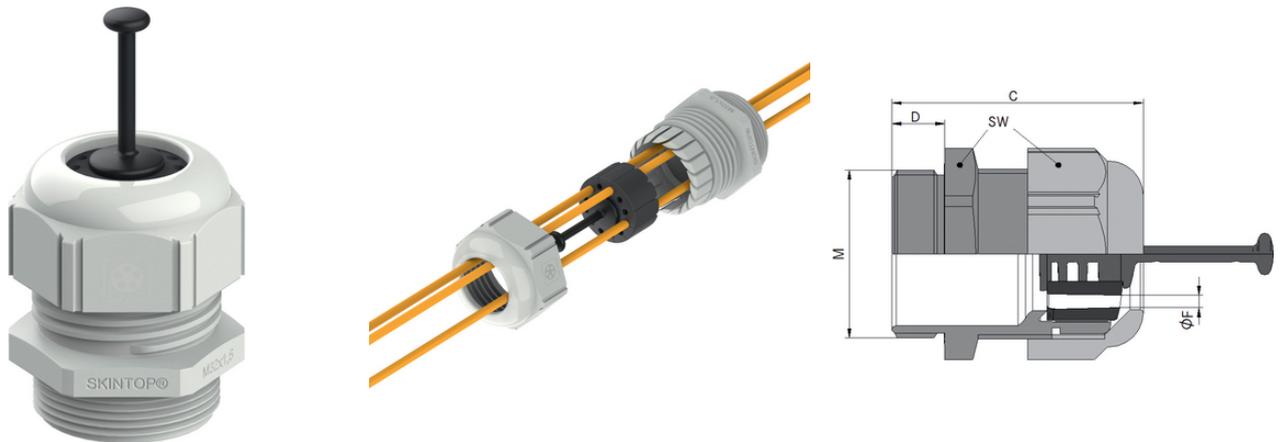

Special sealing insert with 12 x 0-3mm clamping range
Easy assembly and disassembly thanks to the insertion aid
Smooth clamping of sensitive fibre optic cables due to the soft EPDM material
The slotted holes allow the insertion of pre-assembled fiber optical cables

Assembly of fiber optic cables
Broadband expansion
FTTx-
Industry 4.0 applications

DIN EN 60423

DIN IEC 62444

To achieve a high degree of protection, unoccupied holes can be closed with a SKINTOP DIX-DV plug

Counter nut SKINTOP® GMP-GL-M included

(23.04.2024)



SKINTOP® FIBER

:

:

(RAL 7035)

:

Body: Polyamide

Seal: EPDM (uv- and ozone-resistant)

가:

IP 66 (at maximum use of all boreholes)

:

-20°C +100°C

가 VAT 가 가 .

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



SKINTOP® FIBER

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	/ PU
54113180	M 32 x 1,5	0 - 3	36	47.0	10	10

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINTOP® FIBER



(23.04.2024)