

SKINTOP® ST-M Small PU


SKINTOP® ST-M,

가

가

Mit IP69 !

가

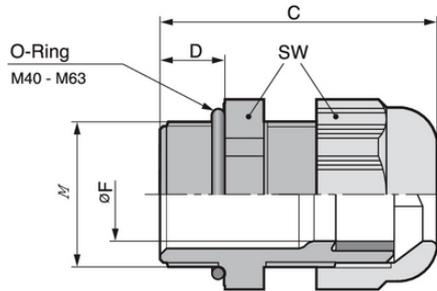

(,)

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINTOP® ST-M Small PU

Off-Shore ,

UL E79903
GGVS: TÜ.EGG.020-95

DIN EN 60423
DIN IEC 62444

SKINTOP® metric

: SKINTOP® GMP-GL-M

ETIM 5:

ETIM 5.0 Class-ID: EC000441
ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000441
ETIM 6.0 Class :

:

T21

Ab Größe M 40 x 1,5 bis M 63 x 1,5 mit O-Ring

:

(: RAL 7001)

:

:

: CR

:

GGVS: TÜ.EGG.020-95

가:

IP 66

IP 68 - 5 bar

IP 69

NEMA Type 1, 12

:

: -40°C +100°C

: -20°C ~ +100°C

가 VAT 가 가 .

(24.04.2024)

SKINTOP® ST-M Small PU

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	/ PU
53110146	ST-M 12 x 1,5	3.5 - 7	15	30.0	8	10
53110147	ST-M 16 x 1,5	4 - 10	19	34.0	8	10
53110148	ST-M 20 x 1,5	6 - 13	25	37.0	9	10
53110149	ST-M 25 x 1,5	8 - 17	30	40.0	10	10
53110150	ST-M 32 x 1,5	9 - 21	36	47.0	10	5
53110151	ST-M 40 x 1,5	16 - 28	46	52.0	10	5
53110068	ST-M 12 x 1,5 + GMP-GL-M	3.5 - 7	15	30.0	8	10
53110069	ST-M 16 x 1,5 + GMP-GL-M	4 - 10	19	34.0	8	10
53110070	ST-M 20 x 1,5 + GMP-GL-M	6 - 13	25	37.0	9	10
53110071	ST-M 25 x 1,5 + GMP-GL-M	8 - 17	30	40.0	10	10
53110072	ST-M 32 x 1,5 + GMP-GL-M	9 - 21	36	47.0	10	5
53110073	ST-M 40 x 1,5 + GMP-GL-M	16 - 28	46	52.0	10	5
53110074	ST-M 50 x 1,5 + GMP-GL-M	27 - 34	55	62.0	12	5
53110075	ST-M 63 x 1,5 + GMP-GL-M	34 - 45	66	71.0	12	5

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16