


SKINTOP® INOX / SKINTOP® INOX-R

SKINTOP® INOX / SKINTOP® INOX-R,

가

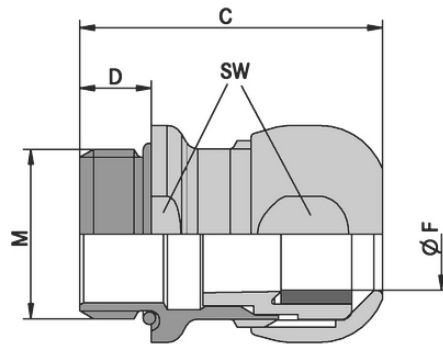

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINTOP® INOX / SKINTOP® INOX-R

(,)

ECOLAB®

DIN EN 1672-2

DIN EN ISO 14159

Security of machinery – Hygienic requirements for the design of machinery
NSF/ANSI 169 ,

DIN EN 60423

DIN IEC 62444

ETIM 5:

ETIM 5.0 Class-ID: EC000441

ETIM 5.0 :

ETIM 6:

ETIM 6.0 Class-ID: EC000441

ETIM 6.0 Class :

:

Body: stainless steel V4A

(1.4404 / 316L)

Insert: polyamide

Sealing: silicone

O-Ring: silicone

가:

IP 68 - 10 bar (M12 - M20)

IP 68 - 5 bar (M25 - M50)

IP 69

NEMA Type 1, 2, 4x, 6, 12

:

-40°C ~ +100°C

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

SKINTOP® INOX / SKINTOP® INOX-R

	Article designation / size	Ø F mm	SW (mm)	, C mm	Thread length D mm	/ PU
SKINTOP® INOX						
53806739	M 12 x 1,5	4 - 7	16	29.3	6.5	5
53806740	M 16 x 1,5	6 - 10	20	32.4	7	5
53806741	M 20 x 1,5	7 - 13	24	35.5	8	5
53806742	M 25 x 1,5	9 - 17	29	39.2	8	5
53806743	M 32 x 1,5	11 - 21	36	44.6	9	5
53806744	M 40 x 1,5	19 - 28	45	51.2	9	5
53806745	M 50 x 1,5	27 - 35	54	56.2	10	5
SKINTOP® INOX-R						
53806749	M 12 x 1,5	3 - 5	16	29.3	6.5	5
53806750	M 16 x 1,5	5 - 7	20	32.4	7	5
53806751	M 20 x 1,5	6 - 10	24	35.5	8	5
53806752	M 25 x 1,5	7 - 13	29	39.2	8	5
53806753	M 32 x 1,5	8 - 15	36	44.6	9	5
53806754	M 40 x 1,5	15 - 23	45	51.2	9	5
53806755	M 50 x 1,5	22 - 29	54	56.2	10	5