

ETHERLINE® ROBUST

, Cat5e Cat.7 PROFINET Type B, TPE Profinet

PROFINET
 Good chemical resistance please see Appendix T1



가 , UV
 가 , , ,



ETHERLINE® ROBUST

(7 가)

EN 50173-3 ISO/IEC 24702 2 3

ISO 4892-2 UV-

EN 50396
IEC 61034-2

7-가

:
TPE
:

ETIM 5:

ETIM 5.0 Class-ID: EC000830

ETIM 5.0 Class- :

ETIM 6:

ETIM 6.0 Class-ID: EC000830

ETIM 6.0 Class :

:

: 8 x

: 10 x

::

100 IEC 61156-6

:

: -50°C +80°C

: -40°C +80°C

가 : EUR 100 , 150 kg. 가 가 . (.) 가 .
T17

www.lappkabel.de/en/cable-standradlengths

PROFINET® PNO (PROFIBUS) .

가 . /

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ETHERLINE® ROBUST

Article number		AWG	(mm)	mm	(kg/km)	(kg/km)
PROFINET Cat.5e						
2170451	ETHERLINE® ROBUST PN Cat.5	2x2x22/7AWG	1.5	6.5	30.4	50
PROFINET Cat.7						
2170452	ETHERLINE® ROBUST PN Cat.7	4x2xAWG23/7	1.5	8.7	48	75
Industrial Ethernet Cat.7						
2170453	ETHERLINE® ROBUST Cat.7 FLEX	4x2xAWG26/7	1	6.2	27	36

(24.04.2024)


©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

ETHERLINE® ROBUST

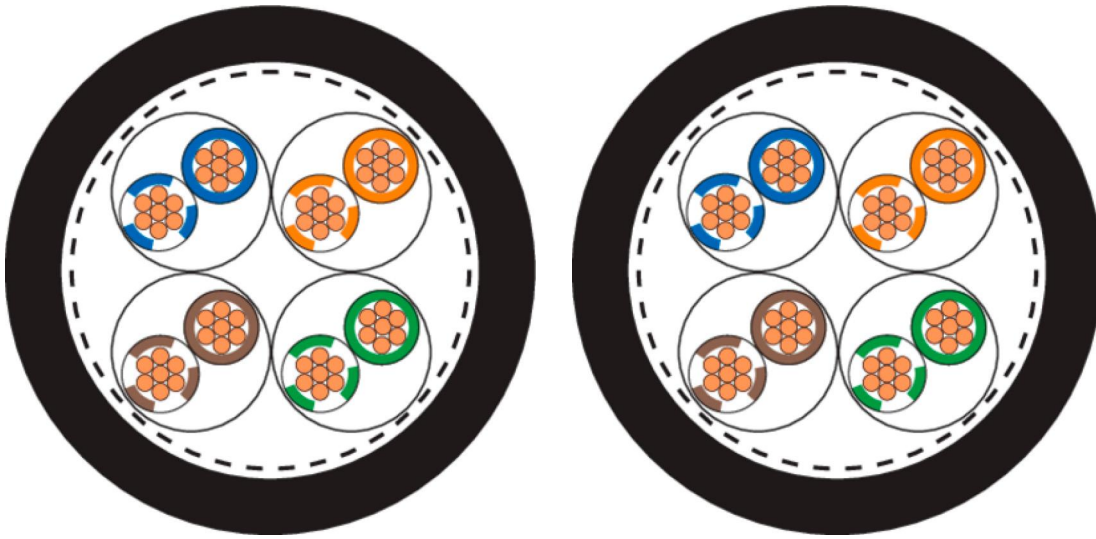

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16