


ETHERLINE® TRAY

Industrial Ethernet cable for general purpose installations, PLTC and CMG- approval acc. to UL and CSA, suitable for EtherNet/IP applications, 1 up to 10 Gbit/s data transmission

PLTC ()

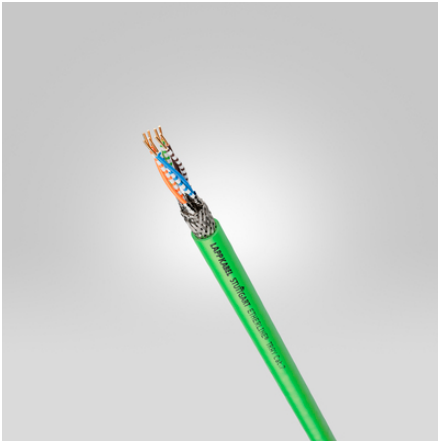

Lapp



4 : 10/100/1000Mbit/s
10Gbit/s CAT.7

EtherNet/IP

Industrial machinery, plant engineering in the USA

: , , ,

(08.05.2024)



ETHERLINE® TRAY

CSA FT4 UL
UL OIL RES I

UL 444 / CSA 22.2 c(UL)us Typ CMG (75°C)
c(UL)us Typ PLTC acc. to UL 13
IEC 61156-5

EIA/TIA 568A, B
TP
PVC

ETIM 5:

ETIM 5.0 Class-ID: EC000830

ETIM 5.0 Class- :

ETIM 6:

ETIM 6.0 Class-ID: EC000830

ETIM 6.0 Class :

:

() 125 V

:

() : 15 x

: 10 x

..

100 IEC 61156-6

:

: -25°C ~+80°C

: -40°C +80°C

가 VAT 가 가 .

(08.05.2024)



ETHERLINE® TRAY

Article number		AWG	mm	(kg/km)	(kg/km)
2170472	ETHERLINE TRAY Cat.7 Y 4x2xAWG22/1	4x2xAWG22/1	8.9	356.14	101

(08.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16