


ETHERLINE® Cat.5 FRNC HYBRID

PUR , Cat.5
AWM 2x2xAWG22/7+4x1,5

HYBRID: +
CAT.5-

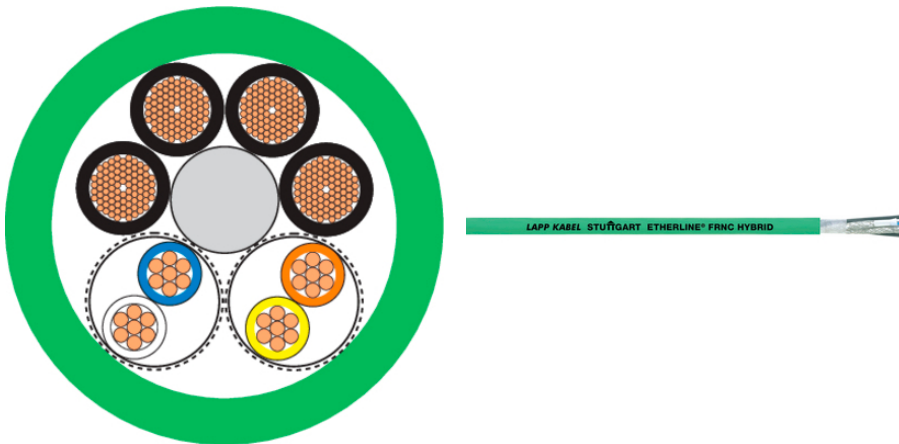

Lapp



2 : , 10/100Mbit/s

EtherCAT EtherNet/IP

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ETHERLINE® Cat.5 FRNC HYBRID

HYBRID: +

UL AWM Style 21282
IEC 60332-1-2

4 x 1.5mm²(AWG16)

: , 7-
:
:

FRNC
: (RAL 6018)

ETIM 5: ETIM 5.0 Class-ID: EC000830
ETIM 5.0 Class- :

ETIM 6: ETIM 6.0 Class-ID: EC000830
ETIM 6.0 Class :

: : 10 x
: 5 x

:
:
: 100 IEC 61156-5

: : -20 ~ +70 °C

가 : EUR 100 , 150 kg. 가 가 . (.) 가 .
T17

www.lappkabel.de/en/cable-standradlengths

: 30 kg or 250 m,

PROFINET® PNO (PROFIBUS)

가 . /

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ETHERLINE® Cat.5 FRNC HYBRID

Article number		AWG	mm	(kg/km)	(kg/km)
2170887	ETHERLINE® Cat.5 FRNC HYBRID	2x2xAWG22/7 + 4x1.5	10.3	94.2	153

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16