


ETHERLINE® PN Cat.5 FLEX

PVC FRNC Cat.5 , UL- , PROFINET- B, 2x2xAWG22/7

CPR: www.lappkabel.com/cpr

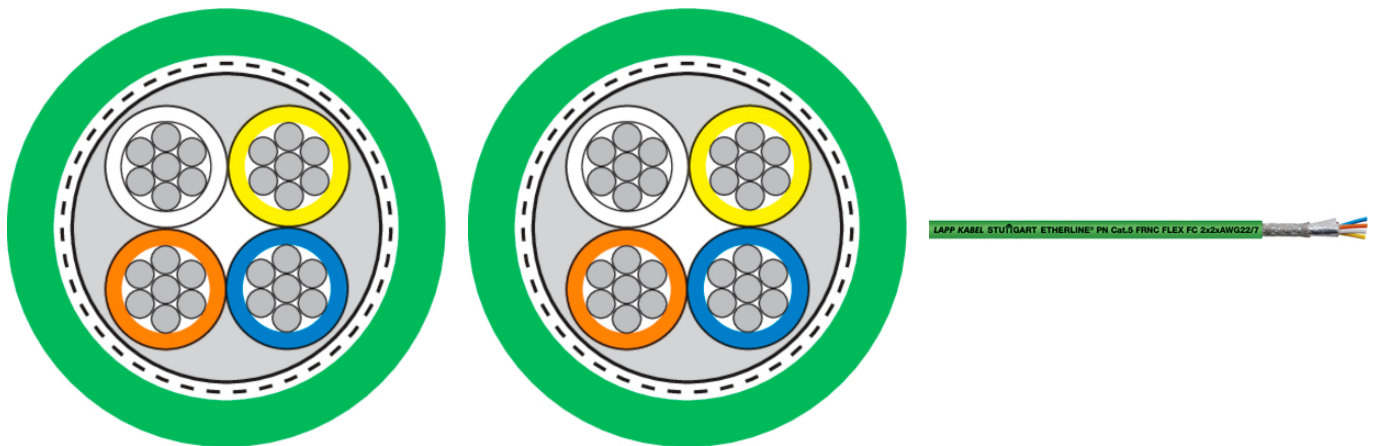

Lapp



PROFINET B 가

2 : , 10/100Mbit/s

(03.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

ETHERLINE® PN Cat.5 FLEX

EN 50173-3 ISO/IEC 24702 2 3

EtherCAT EtherNet/IP
(7 가)

CSA FT4 UL
CAT.5-
FRNC :
(FC)

: UL/CSA (CMG)
ETHERLINE® PN CAT.5 Y FLEX FC : ECOLAB®

7
: PE or PP

PVC FRNC
:
PVC FRNC
: (RAL 6018)

ETIM 5: ETIM 5.0 Class-ID: EC000830
ETIM 5.0 Class- :

ETIM 6: ETIM 6.0 Class-ID: EC000830
ETIM 6.0 Class :

: () 125 V

:
FRNC cable:
fixed: 4 x outer diameter
during installation: 8 x outer diameter
PVC cable:
Fixed installation: 3 x outer diameter
Flexing: 7 x outer diameter

:
Core/core: 2000 V
Core/screen: 2000 V

∴
100 Ω ± 15%

:
: -25°C to +80°C
: -25°C to +80°C

PVC
: -40°C to +80°C
: -20°C to +60°C

ETHERLINE® PN Cat.5 FLEX

가 가 . (.) 가 .
www.lappkabel.de/en/cable-standradlengths
: ≤ 30 kg or ≤ 250 m,
PROFINET® PNO (PROFIBUS) .
가 . /
가 VAT 가 가 .



ETHERLINE® PN Cat.5 FLEX

Article number		AWG	(mm)	mm	(kg/km)	(kg/km)
PVC						
2170886	ETHERLINE® PN Cat.5 Y FLEX FC	2 x 2 x AWG22/7	1.5	6.5	31.3	67
FRNC						
2170890	ETHERLINE® PN Cat.5e FRNC FLEX FC	2 x 2 x AWG22/7	1.5	6.5	31.2	65



ETHERLINE® PN Cat.5 FLEX



(03.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16