

ETHERLINE® PN FD Cat.5 M12

PROFINET

M12

UL-
Cat.5 2


Profinet Type C,

M12/M12,

D- , PUR

2170894
가

www.lappgroup.com/assemblyfinderor

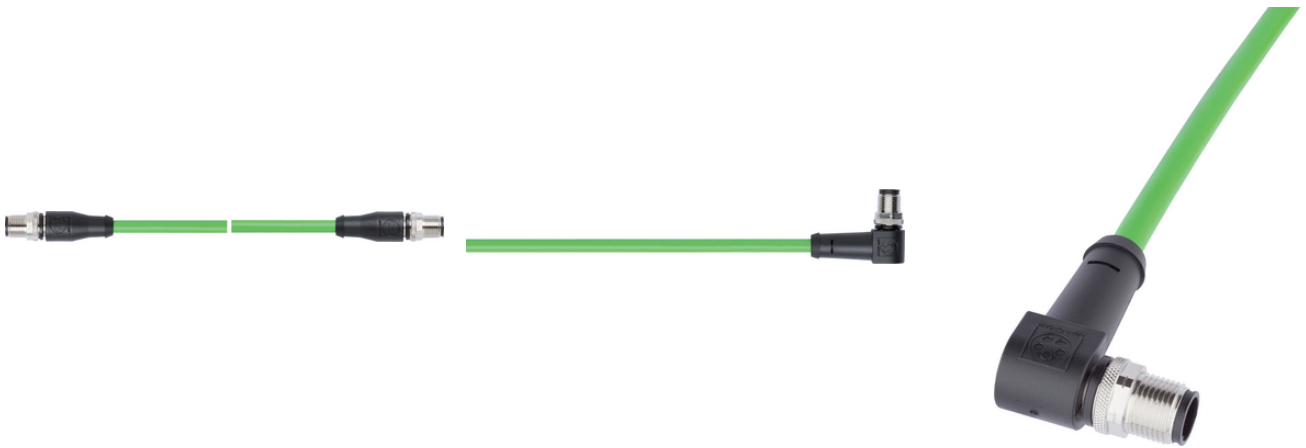

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

ETHERLINE® PN FD Cat.5 M12

2

가

EtherCAT EtherNet/IP

Cat.5e class D
2 : , 10/100Mbit/s

UL UL/CSA (CMX)
: E249137

Braided conductor, 2x2x AWG22/7

PUR :
: (RAL 6018) 가
4 M12 D
M12

ETIM 5: ETIM 5.0 Class-ID: EC002599
ETIM 5.0 class : ()
ETIM 6: ETIM 6.0 Class-ID: EC002599
ETIM 6.0 Class :
: 10 x
가: IP69
: -20°C +60°C
: -30°C +70°C

가 VAT 가 가 . 가 가 (.) 가 .

Article number		(m)	kg/1.000 pieces
M12	M12		
2171121	IE-PNC-5-M12D-S-0,5-P-2-22-FD-M12D-S	0.5	15.65
2171049	IE-PNC-5-M12D-S-1-P-2-22-FD-M12D-S	1	31.3
2171050	IE-PNC-5-M12D-S-2-P-2-22-FD-M12D-S	2	62.6
2171051	IE-PNC-5-M12D-S-3-P-2-22-FD-M12D-S	3	93.9
2171052	IE-PNC-5-M12D-S-5-P-2-22-FD-M12D-S	5	156.5
2171053	IE-PNC-5-M12D-S-10-P-2-22-FD-M12D-S	10	313
2171054	IE-PNC-5-M12D-S-20-P-2-22-FD-M12D-S	20	626
M12	M12		
2171122	IE-PNC-5-M12D-A-0,5-P-2-22-FD-M12D-S	0.5	15.65
2171061	IE-PNC-5-M12D-A-1-P-2-22-FD-M12D-S	1	31.3
2171062	IE-PNC-5-M12D-A-2-P-2-22-FD-M12D-S	2	62.6
2171063	IE-PNC-5-M12D-A-3-P-2-22-FD-M12D-S	3	93.9
2171064	IE-PNC-5-M12D-A-5-P-2-22-FD-M12D-S	5	156.5
2171065	IE-PNC-5-M12D-A-10-P-2-22-FD-M12D-S	10	313
2171066	IE-PNC-5-M12D-A-20-P-2-22-FD-M12D-S	20	626
M12			
2172201	IE-PNC-5-M12D-S-0,5-P-2-22-FD-OE	0.5	15.65
2171055	IE-PNC-5-M12D-S-1-P-2-22-FD-OE	1	31.3
2171056	IE-PNC-5-M12D-S-2-P-2-22-FD-OE	2	62.6
2171057	IE-PNC-5-M12D-S-3-P-2-22-FD-OE	3	93.9
2171058	IE-PNC-5-M12D-S-5-P-2-22-FD-OE	5	156.5
2171059	IE-PNC-5-M12D-S-10-P-2-22-FD-OE	10	313
2171060	IE-PNC-5-M12D-S-20-P-2-22-FD-OE	20	626
M12			
2172204	IE-PNC-5-M12D-A-0,5-P-2-22-FD-OE	0.5	15.65
2171067	IE-PNC-5-M12D-A-1-P-2-22-FD-OE	1	31.3
2171068	IE-PNC-5-M12D-A-2-P-2-22-FD-OE	2	62.6
2171069	IE-PNC-5-M12D-A-3-P-2-22-FD-OE	3	93.9
2171070	IE-PNC-5-M12D-A-5-P-2-22-FD-OE	5	156.5
2171071	IE-PNC-5-M12D-A-10-P-2-22-FD-OE	10	313
2171072	IE-PNC-5-M12D-A-20-P-2-22-FD-OE	20	626
2171250	-	-	15.65
2171251	IE-PNC-5-M12D-S-1-P-2-22-FD-M12DF-S	-	31.3
2171255	IE-PNC-5-M12D-S-10-P-2-22-FD-M12DF-S	-	156.5

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ETHERLINE® PN FD Cat.5 M12

Article number		(m)	kg/1.000 pieces
2171252	-	-	31.3
2171253	IE-PNC-5-M12D-S-3-P-2-22-FD-M12DF-S	-	62.6
2171254	IE-PNC-5-M12D-S-5-P-2-22-FD-M12DF-S	-	93.9

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

ETHERLINE® PN FD Cat.5 M12



(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16