


ETHERLINE® Cat.6A

Ethernet cable Category 6A, Class EA for fixed installation - verified up to 500 MHz

Cat.6A
PVC PUR , 4x2xAWG22/1

CPR: www.lappkabel.com/cpr
PROFINET (4)
CAT.6A qualified for 10Gbit/s

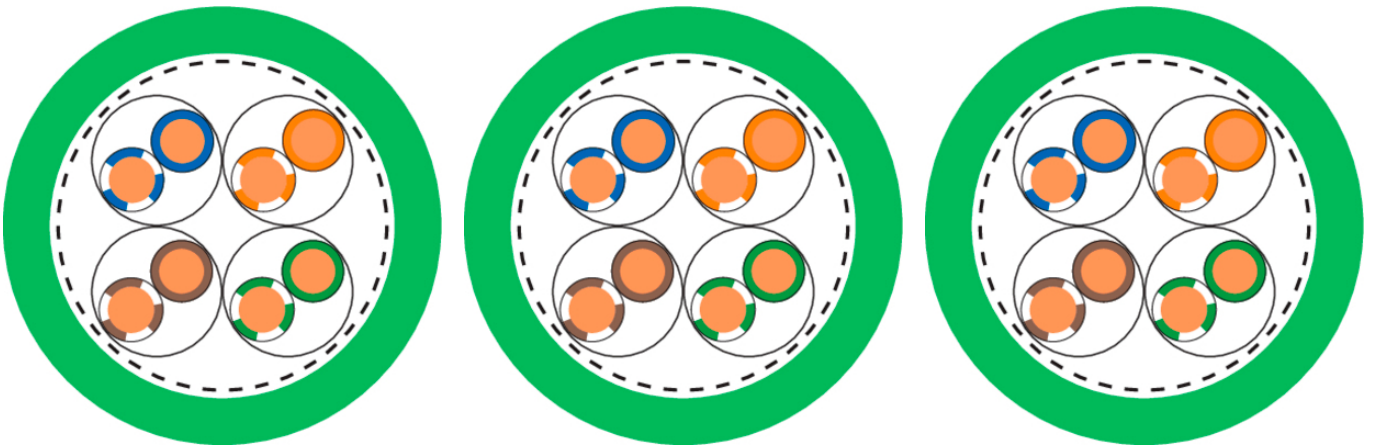

Lapp



가

4 : 100Mbit/s ~ 10Gbit/s

EN 50173-3 ISO/IEC 24702

2 3

EtherCAT EtherNet/IP

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

ETHERLINE® Cat.6A

PUR

PVC

가

AWG22
: (PE)
S/FTP:
: (RAL 6018)

ETIM 5.0/6.0 Class-ID: EC000830
ETIM 5.0/6.0 Class :
ETIM 6:
ETIM 6.0 Class-ID: EC000830
ETIM 6.0 Class :
: () 125 V
: 10 x
: 100 Ω ± 5 Ohm (> 1 MHz)
PUR
: -40°C ~+80°C
,
: -25°C ~+80°C
PVC
: -30°C ~+80°C

www.lappkabel.de/en/cable-standradlengths
: ≤ 30 kg or ≤ 250 m,
(e.g. 1 x 500 m or 5 x 100 m).
PROFINET® PNO (PROFIBUS)

가 VAT 가 가 .



ETHERLINE® Cat.6A

Article number		AWG	(mm)	mm	(kg/km)	(kg/km)
2170466	ETHERLINE® Cat.6 _A H	4 x 2 x AWG22/1	1.5	8.7	53	99
PUR						
2170465	ETHERLINE® CAT.6 _A P	4 x 2 x AWG22/1	1.5	8.7	53	91
PVC						
2170464	ETHERLINE® Cat.6 _A Y	4 x 2 x AWG22/1	1.5	8.7	53	98



ETHERLINE® Cat.6A



(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16