
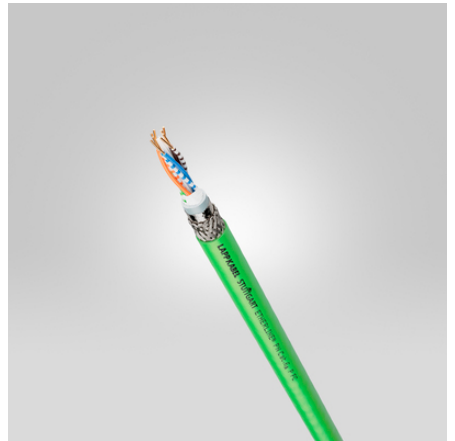


# ETHERLINE® PN Cat.6A FC

Cat 6A, FC 가 class EA - 500MHz  
 , PVC Cat.6A PUR , FC 4x2xAWG23/1

FC  
 PROFINET (4 )  
 CAT.6A qualified for 10Gbit/s

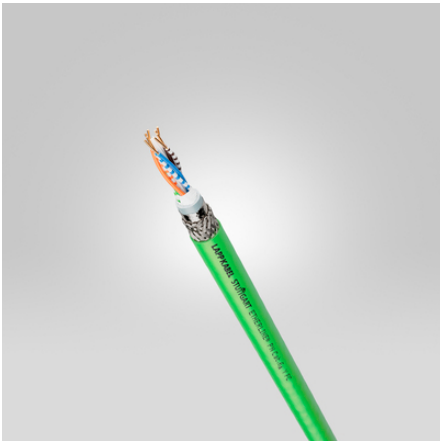

Lapp



가

4 : 100Mbit/s ~ 10Gbit/s

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# ETHERLINE® PN Cat.6A FC

EN 50173-3 ISO/IEC 24702 2 3

EtherCAT EtherNet/IP

PVC 가  
FRNC  
PUR

UL approvals see data sheet  
IEC 60332-1-2

AWG23  
: (PE)  
SF/UTP: , 2 , 4  
: (RAL 6018 )

: ( ) 125 V  
: : 8 x  
:  
.: 100 IEC 61156-5  
:

가 : EUR 100 150 kg. T17

www.lappkabel.de/en/cable-standradlengths  
: 30 kg or 250 m,

(e.g. 1 x 500 m or 5 x 100 m ).

PROFINET® PNO (PROFIBUS )

가 VAT 가 가 .

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# ETHERLINE® PN Cat.6A FC

Article number		AWG	(mm)	mm	(kg/km)	(kg/km)
PVC						
2170583	ETHERLINE® PN CAT.6 <sub>A</sub> Y FC	4x2xAWG23/1	1.1	8.7	53	98
2170584	ETHERLINE® PN CAT.6 <sub>A</sub> FRNC FC	4x2xAWG23/1	1.1	8.7	53	91
PUR						
2170585	ETHERLINE® PN CAT.6 <sub>A</sub> P FC	4x2xAWG23/1	1.1	8.7	53	99

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# ETHERLINE® PN Cat.6A FC



(23.04.2024)

©2024 Lapp Group - all rights reserved.  
<http://lappkorea.lappgroup.com>  
data sheet

PN 0456 / 02\_03.16