


# ETHERLINE® Cat.7

, PVC Cat.7 PUR , 4x2xAWG22/1

PROFINET (4 )  
10Gbit/s CAT.7

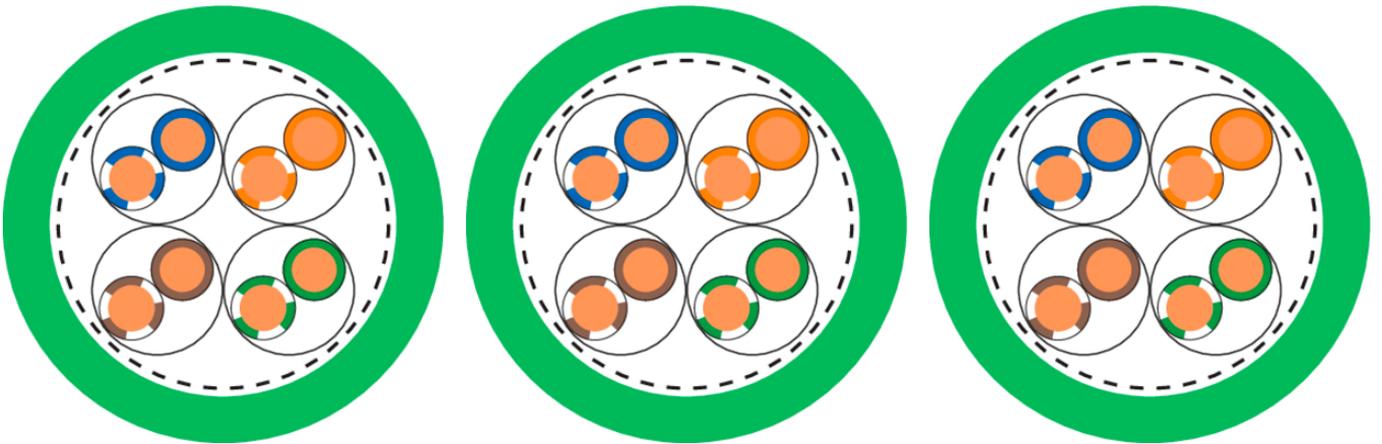

Lapp



가

4 : 100Mbit/s ~ 10Gbit/s

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# ETHERLINE® Cat.7

EN 50173-3 ISO/IEC 24702 2 3

100Mbit/s : 100m10Gbit/s : 100m  
EtherCAT EtherNet/IP

PUR

PVC 가

AWG22  
(PE)  
S/FTP:  
(RAL 6018 )

ETIM 5:

ETIM 5.0 Class-ID: EC000830

ETIM 5.0 Class- :

( ) 125 V

: 10 x

100 ohm at 1 - 100 MHz

PVC: -30°C ~ +80°C

PUR: -40°C ~ +80°C

: -25°C to +80°C

가 VAT 가 가 .

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



# ETHERLINE® Cat.7

| Article number |                    | AWG             | (mm) | mm  | (kg/km) | (kg/km) |
|----------------|--------------------|-----------------|------|-----|---------|---------|
| 2170476        | ETHERLINE® Cat.7 H | 4 x 2 x AWG22/1 | 1.5  | 8.7 | 53      | 99      |
| PUR            |                    |                 |      |     |         |         |
| 2170475        | ETHERLINE® Cat.7 P | 4 x 2 x AWG22/1 | 1.5  | 8.7 | 53      | 91      |
| PVC            |                    |                 |      |     |         |         |
| 2170474        | ETHERLINE® Cat.7 Y | 4 x 2 x AWG22/1 | 1.5  | 8.7 | 53      | 98      |

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



## ETHERLINE® Cat.7



(23.04.2024)

©2024 Lapp Group - all rights reserved.  
<http://lappkorea.lappgroup.com>  
data sheet

PN 0456 / 02\_03.16