


ETHERLINE® Cat.7

, PVC Cat.7 PUR , 4x2xAWG22/1

PROFINET (4)
10Gbit/s CAT.7

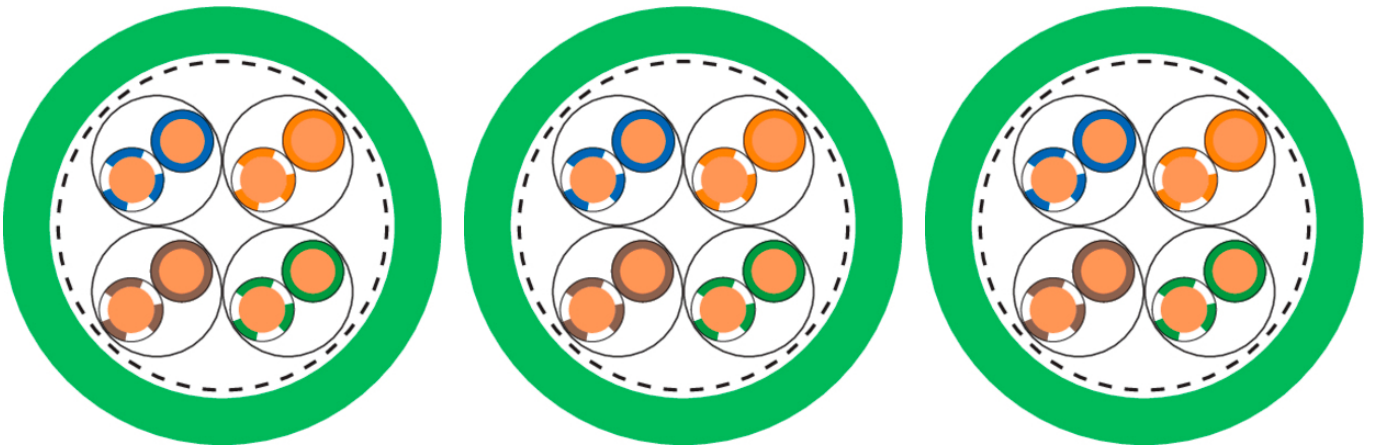

Lapp



가

4 : 100Mbit/s ~ 10Gbit/s

(08.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ETHERLINE® Cat.7

EN 50173-3 ISO/IEC 24702 2 3

100Mbit/s : 100m10Gbit/s : 100m
EtherCAT EtherNet/IP

PUR

PVC 가

AWG22
(PE)
S/FTP:
(RAL 6018)

ETIM 5:

ETIM 5.0 Class-ID: EC000830

ETIM 5.0 Class- :

() 125 V

: 10 x

100 ohm at 1 - 100 MHz

PVC: -30°C ~ +80°C

PUR: -40°C ~ +80°C

: -25°C to +80°C

가 VAT 가 가 .

(08.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ETHERLINE® Cat.7

Article number		AWG	(mm)	mm	(kg/km)	(kg/km)
2170476	ETHERLINE® Cat.7 H	4 x 2 x AWG22/1	1.5	8.7	53	99
PUR						
2170475	ETHERLINE® Cat.7 P	4 x 2 x AWG22/1	1.5	8.7	53	91
PVC						
2170474	ETHERLINE® Cat.7 Y	4 x 2 x AWG22/1	1.5	8.7	53	98

(08.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



ETHERLINE® Cat.7



(08.05.2024)

©2024 Lapp Group - all rights reserved.
<http://lappkorea.lappgroup.com>
data sheet

PN 0456 / 02_03.16