


# ETHERLINE® PN Cat.7

Cat 7, class F - 600MHz  
 , PVC Cat.7 PUR , 4x2xAWG23/1

PROFINET (4 )  
 10Gbit/s CAT.7

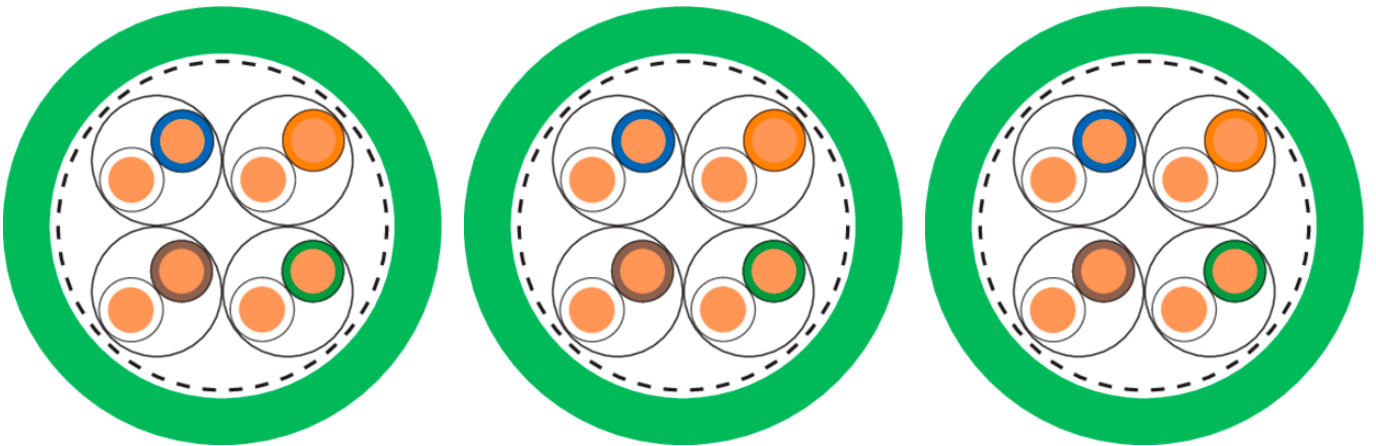

가

4 : 100Mbit/s ~ 10Gbit/s

(30.04.2024)

# ETHERLINE® PN Cat.7

EN 50173-3 ISO/IEC 24702 2 3

EtherCAT EtherNet/IP

PUR

FRNC

IEC 60332-1-2  
ACC. IEC 60811-2-1  
UL approvals see data sheet

AWG23

(PE)

S/FTP:

: (RAL 6018 )

ETIM 5:

:  
:  
:  
:  
:  
:  
:

ETIM 5.0/6.0 Class-ID: EC000830

ETIM 5.0/6.0 Class :

( ) 125 V

: 8 x

/ : 1500 V

Core/screen: 1500 V eff.

100 ± 5 (>1MHz)

PVC/FRNC: -30 °C ~ +80 °C

PUR: -40°C +80°C

Lapp Kabel PROFIBUS user organisation (PNO)

가 VAT 가 가 .

(30.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



## ETHERLINE® PN Cat.7

Article number		AWG	(mm)	mm	(kg/km)	(kg/km)
2170605	ETHERLINE® PN CAT.7 Y A	2 x 4 x AWG23/1	1.4	8.1	-	80
2170606	ETHERLINE® PN CAT.7 FRNC A	2 x 4 x AWG23/1	1.4	8.1	40	80
2170607	ETHERLINE® PN CAT.7 P A	2 x 4 x AWG23/1	1.4	8.1	40	80

(30.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



## ETHERLINE® PN Cat.7



(30.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16