
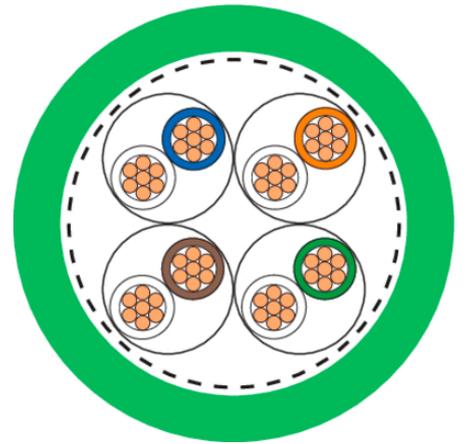


ETHERLINE® PN Cat.7 FLEX

Cat.7, 가 class F - 600MHz

Cat.7, : PVC , 4x2xAWG23/7

PROFINET (4)
10Gbit/s CAT.7

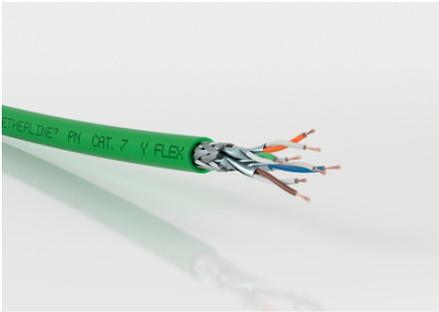

Lapp



가

4 : 100Mbit/s ~ 10Gbit/s

EN 50173-3 ISO/IEC 24702 2 3

(26.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

ETHERLINE® PN Cat.7 FLEX

EtherCAT EtherNet/IP

FRNC : PVC 가

IEC 60332-1-2
UL approvals see data sheet

7-가
(PE)
S/FTP:
: (RAL 6018)

ETIM 5:	ETIM 5.0/6.0 Class-ID: EC000830
:	ETIM 5.0/6.0 Class :
:	() 125 V
:	: 4 x
:	: 8 x
:	/ : 1500 V
:	Core/screen: 1500 V eff.
:	100 ± 5 Ohm (> 1 MHz)
:	: -30°C +80°C
:	Occasional flexing: -5°C ~ +50°C

가 VAT 가 가 .



ETHERLINE® PN Cat.7 FLEX

Article number		AWG	(mm)	mm	(kg/km)
2170609	ETHERLINE® PN CAT.7 FRNC FLEX A	4x2xAWG23/7	1.5	8.7	45
2170608	ETHERLINE® PN CAT.7 Y FLEX A	4x2xAWG23/7	1.5	8.7	45

(26.04.2024)


©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

ETHERLINE® PN Cat.7 FLEX

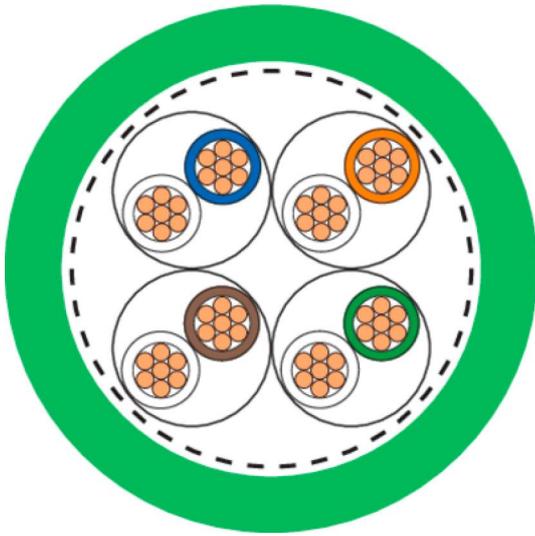

(26.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16