


# ETHERLINE® LAN 1200 Cat.7A

Cat 7A/ class FA - 1200MHz

Category 7A/ class FA - 1200MHz

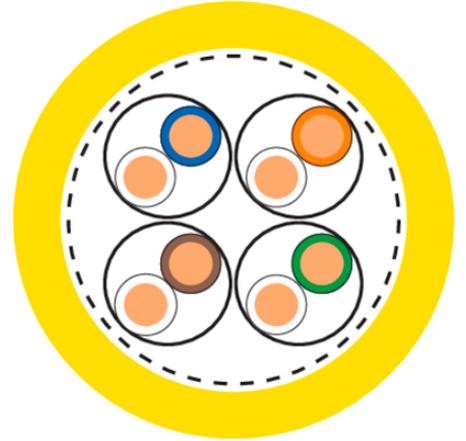

EN 50173 ISO/IEC 11801

LAN

가  
3  
3  
90 m + ( 10 m ) ( ) ISO/IEC 11801 EN 50173 ,100 m .(

IEEE 802.3: 10/100/1000Base-T, 10GBase-T  
IEEE 802.5: ISDN; FDDI; ATM;  
IEC 60332-1-2  
IEC 60332-3-24 , 가

IEEE 802.3at: PoE, VoIP

Lapp Kabel LAN CAT.5e EIA/TIA-568 TSB36 ISO/IEC 11801 EN 50173 ( FA - )

4x2xAWG23/1,  
2x (4x2xAWG23)  
: PE  
S/FTP:

(23.04.2024)

# ETHERLINE® LAN 1200 Cat.7A

:  
: (RAL 7032)

:

ETIM 6:

:

..

:

ETIM 5.0 Class-ID: EC000830

ETIM 5.0 Class- :

ETIM 6.0 Class-ID: EC000830

ETIM 6.0 Class :

: 4 x

: 8 x

100 ± 15%

: -20°C ~+60°C

: 0 °C to +50 °C

가 : EUR 100 150 kg.

:

T17

가 VAT 가 가 .



ETHERLINE® LAN 1200 Cat.7A

Article number		AWG	(mm)	mm		(kg/km)	(kg/km)
ETHERLINE® LAN 1200 Cat.7A 2x(4x2xAWG23) LSZH duplex							
2170974	ETHERLINE® LAN 1200 Cat.7A 4x2xAWG23 LSZH	4 x 2 x AWG23/1	1.33	7.5		26	58
2170975	ETHERLINE® LAN 1200 Cat.7A 2x(4x2xAWG23) LSZH duplex	2x (4x2xAWG23/1)	1.33	15.2		52	114

(23.04.2024)


©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16

# ETHERLINE® LAN 1200 Cat.7A

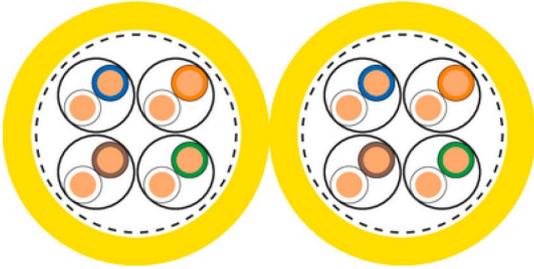

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16