


UNITRONIC® SENSOR M8-M12

M12 M8
/ , M12 M8, PUR , 3 , / , LED, A , IP65 / IP67 / IP68,

www.lappgroup.com/assemblyfinder 가

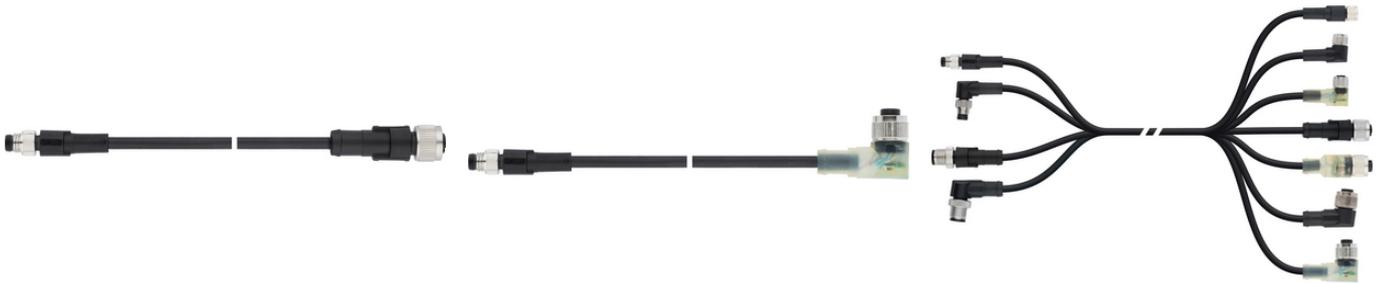

Lapp



Space-saving due to compact dimensions.

가

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

UNITRONIC® SENSOR M8-M12

가 가

UV-

PWIS PVC

DIN VDE 0472
UL : E249137
: UL 1581 FT-2

: 0.25 mm²

: 3- : bn (1), bu (3), bk (4)
: PUR,

ETIM 5:

ETIM 5.0 Class-ID: EC001855
ETIM 5.0 Class: -

ETIM 6:

ETIM 6.0 Class-ID: EC001855
ETIM 6.0 Class :

:

: CuSn : Ni/Au
: TPU, ,

:

: 5 x

: 10 x

가:

IP65/IP67/IP68

():

/
-25°C +90°C (PUR/PVC)

-40°C - +80°C

-25°C - +80°C

:

A-Standard

(A):

4 A

, 가 가 (.) 가 .

가 VAT 가 가 .

UL-Zertifizierungen sind dem Datenblatt zu entnehmen

(23.04.2024)



UNITRONIC® SENSOR M8-M12

		/	(m)	Design	LED	(V)	PU
3-							
22260241	AB-C3-M8MS-0,3PU R-M12FS	3	0.3	-	no	60	1
22260242	AB-C3-M8MS-0,6PU R-M12FS	3	0.6	-	no	60	1
22260243	AB-C3-M8MS-1,0PU R-M12FS	3	1	-	no	60	1
22260244	AB-C3-M8MS-2,0PU R-M12FS	3	2	-	no	60	1
22260245	AB-C3-M8MS-0,3PU R-M12FA	3	0.3	-	no	60	1
22260246	AB-C3-M8MS-0,6PU R-M12FA	3	0.6	-	no	60	1
22260247	AB-C3-M8MS-1,0PU R-M12FA	3	1	-	no	60	1
22260248	AB-C3-M8MS-2,0PU R-M12FA	3	2	-	no	60	1
22260271	AB-C3-M8MS-0,3PU R-M12FA-2L	3	0.3	-	2 LEDs	24	1
22260272	AB-C3-M8MS-0,6PU R-M12FA-2L	3	0.6	-	2 LEDs	24	1
22260273	AB-C3-M8MS-1,0PU R-M12FA-2L	3	1	-	2 LEDs	24	1
22260274	AB-C3-M8MS-2,0PU R-M12FA-2L	3	2	-	2 LEDs	24	1

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

UNITRONIC® SENSOR M8-M12



(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16