


EPIC® POWER LS1 D6

EPIC® LS1 가

Made in Germany

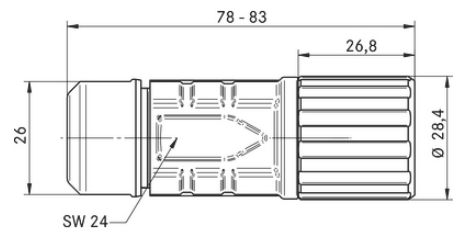

(20.07.2024)

EPIC® POWER LS1 D6



SKINTOP®



EMC

ETIM 5:	ETIM 5.0 Class-ID: EC002635
	ETIM 5.0 class : ()
ETIM 6:	ETIM 6.0 Class-ID: EC002635
	ETIM 6.0 Class : ()
(V):	630 V (2 mm)
	250 V (1 mm)
:	6 kV (2 mm)
	4 kV (1 mm)
(A):	26A/3+PE+4, 25A/5+PE(2mm)
	7 A (1 mm)
:	3
:	< 4 mOhm
:	
/ :	3+PE+4(2mm/1mm)
	5+PE(2mm)
:	: 0.5 - 4.0 mm ² (2 mm contacts)
	: 0.14 - 1.0 mm ² (1 mm contacts)
:	:
	: PA,
	: FPM
가:	IP68 (10h/1m)
:	500

(20.07.2024)



EPIC® POWER LS1 D6

VDE- : : VDE-REG. B25
UL : E249137
-25°C ~+125°C

가 VAT 가 가 .

(20.07.2024)



EPIC® POWER LS1 D6

	Article description		Clamping range min	Clamping range max	Clamping range in mm		Packaging unit
LS1 D6, , 6 ,							
73000004	LS1 D6	6	8.5	11	8.5 - 11	5+PE	5
73000006	LS1 D6	-	8.5	11	8.5 - 11	5+PE	20
73000005	LS1 D6	6	10.5	15.5	10.5 - 15.5	5+PE	5
73000007	LS1 D6	-	10.5	15.5	10.5 - 15.5	5+PE	20
76123000	LS1 D6	6	7.5	15.5	7.5 - 15.5	5+PE	5
76123510	LS1 D6	-	7.5	15.5	7.5 - 15.5	5+PE	20
44420091	4mm ² 2mm D6 LS1	6	14	17	14 - 17	5+PE	5
44420090	LS1 D6	-	14	17	14 - 17	5+PE	20
LS1 D6, , 8 ,							
73000000	LS1 D6	8	8.5	11	8.5 - 11	3+PE+4	5
73000002	LS1 D6	-	8.5	11	8.5 - 11	3+PE+4	20
73000001	LS1 D6	8	10.5	15.5	10.5 - 15.5	3+PE+4	5
73000003	LS1 D6	-	10.5	15.5	10.5 - 15.5	3+PE+4	20
76124000	LS1 D6	8	7.5	15.5	7.5 - 15.5	3+PE+4	5
76124510	LS1 D6	-	7.5	15.5	7.5 - 15.5	3+PE+4	20
44420089	4mm ² 2mm D6 LS1	8	14	17	14 - 17	3+PE+4	5
44420088	LS1 D6	-	14	17	14 - 17	3+PE+4	20

(20.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16