


**EPIC® POWER LS1.5 D6**

EPIC® LS1.5 가

EMC

Made in Germany

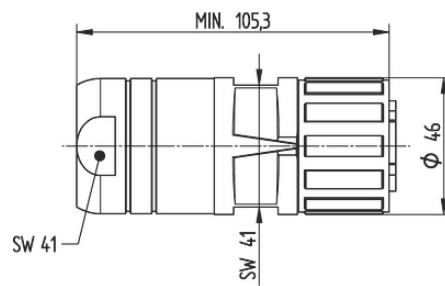

가

가 EMC

(24.04.2024)

# EPIC® POWER LS1.5 D6

ETIM 5:	ETIM 5.0 Class-ID: EC002635
	ETIM 5.0 class : ( )
ETIM 6:	ETIM 6.0 Class-ID: EC002635
	ETIM 6.0 Class : ( )
(V):	630 V (3.6 mm )
	250 V (2 mm )
:	6 kV (3.6 mm )
	4 kV (2 mm )
(A):	70 A (3.6-mm ) 25 °C
	30 A (2-mm ) at 25 °C
:	3
:	
/ :	3+PE+2(3.6mm/2mm)
	3+PE+4(3.6mm/2mm)
:	: 0.75 - 10 mm <sup>2</sup> (3.6 mm )
	: 0.14 - 4.0 mm <sup>2</sup> (2 mm )
:	:
	: PA,
	: FPM
가:	IP 67
:	50
:	-20 °C a ž +125 °C

가 VAT 가 가 .

(24.04.2024)



# EPIC® POWER LS1.5 D6

	Article description	Clamping range min	Clamping range max		/ PU
LS1.5 D6					
44429310	EPIC® POWER LS1.5 D6	9	14	3+PE+2	1
44429311	EPIC® POWER LS1.5 D6	14	20.5	3+PE+2	1
44429312	EPIC® POWER LS1.5 D6	20.5	26.5	3+PE+2	1
44429313	EPIC® POWER LS1.5 D6	9	14	3+PE+4	1
44429314	EPIC® POWER LS1.5 D6	14	20.5	3+PE+4	1
44429315	EPIC® POWER LS1.5 D6	20.5	26.5	3+PE+4	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16