


EPIC® M-D 1.0 D-Sub stamped contacts-on-reel

EPIC®

2가

Two crimp areas with wire and insulation crimp

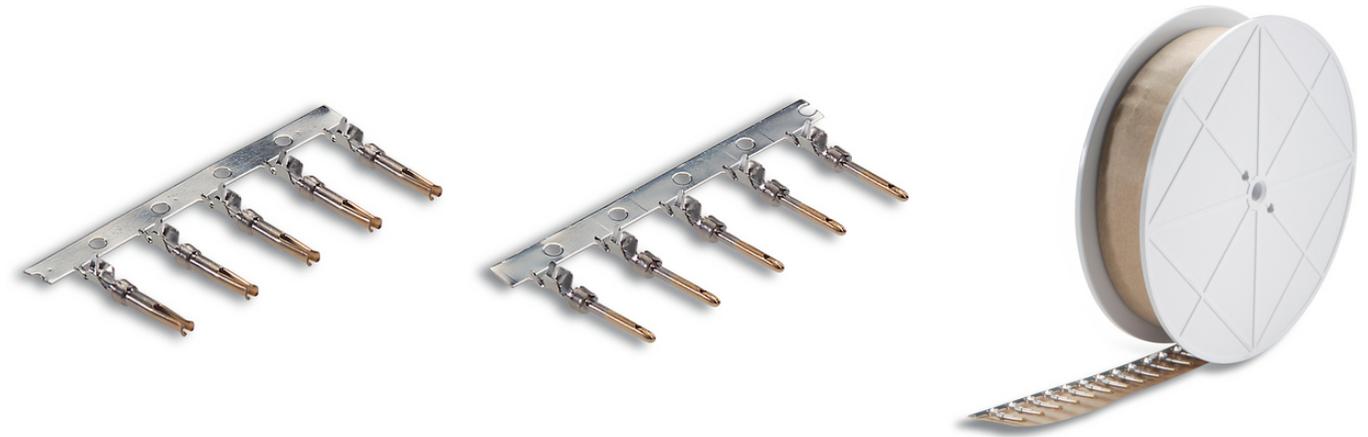

ETIM 5:

ETIM 5.0 Class-ID: EC000796

ETIM 5.0 class :

ETIM 6:

ETIM 6.0 Class-ID: EC000796

ETIM 6.0 Class-Description: Contact for industrial connectors

가 VAT 가 가 .

(20.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



EPIC® M-D 1.0 D-Sub stamped contacts-on-reel

	Article description	Contact type	(mm ²)		(mm)		Packaging unit
44429011	EPIC® D-SUB SCBG AU G2 0,08-0,22 (500)		0.08 - 0.22	Au (0.8 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429007	EPIC® D-SUB BCBG AU G2 0,08-0,22 (500)		0.08 - 0.22	Au (0.8 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429013	EPIC® D-SUB SCBG AU G3 0,08-0,22 (500)		0.08 - 0.22	Au (0.1 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429009	EPIC® D-SUB BCBG AU G3 0,08-0,22 (500)		0.08 - 0.22	Au (0.1 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429012	EPIC® D-SUB SCBG AU G2 0,22-0,56 (500)		0.22 - 0.56	Au (0.8 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429008	EPIC® D-SUB BCBG AU G2 0,22-0,56 (500)		0.22 - 0.56	Au (0.8 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429014	EPIC® D-SUB SCBG AU G3 0,22-0,56 (500)		0.22 - 0.56	Au (0.1 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429010	EPIC® D-SUB BCBG AU G3 0,22-0,56 (500)		0.22 - 0.56	Au (0.1 µm)	2.5 + 0.5	1 (Reel) (PU) = 500	1
44429030	EPIC® D-SUB SCBG AU G3 0,22-0,56 (10k)		0.22 - 0.56	Au (0.1 µm)	2.5 + 0.5	1 reel (PU) = 10.000 contacts	1
44429031	EPIC® D-SUB BCBG AU G3 0,22-0,56 (10k)		0.22 - 0.56	Au (0.1 µm)	2.5 + 0.5	1 reel (PU) = 10.000 contacts	1

(20.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

EPIC® M-D 1.0 D-Sub stamped contacts-on-reel



(20.07.2024)

©2024 Lapp Group - all rights reserved.
<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16