


EPIC® H-A 3 MTG

UL50E

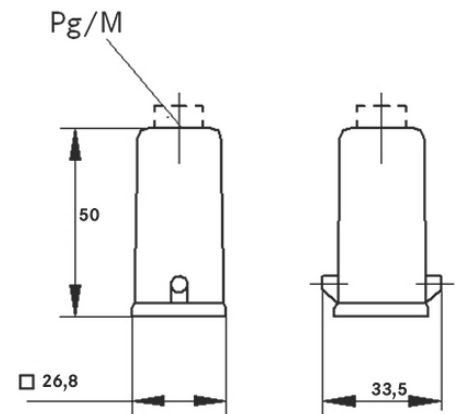

The EPIC® H-A 3 series comprises the smallest housings in the heavy-duty industrial connector range and ensures secure connections in the smallest of spaces.
The hood housing is mateable with many commercially available housings (panel-mount base, surface-mount base or coupler hood housings).
Locking is via single lever on the counterpart.
With threaded hole for use with a corresponding cable gland.
The arrow as a new design element on the surface of the housing is easy to feel and simplifies plugging in spatially confined and possibly poorly visible application areas.

To protect the connector insert from environmental influences.
For use with many EPIC® rectangular connector inserts.

(24.04.2024)



EPIC® H-A 3 MTG

For power supply connection of devices and machines in various applications.
Withstands high environmental and mechanical stresses.

가 /

ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 class :

ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

:

: - - ,

:

가:

IP 65 (latched)

NEMA 250, UL50E: 12, 4 (latched)

VDE- :

: VDE-REG. : B437

UL- :

UL : E75770

:

-40°C to +100°C, short-term up to +125°C

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



EPIC® H-A 3 MTG

	Article description	M	PG					/ PU
H-A : ()								
10512100	H-A 3 MTgv	-	11	-	-	-	-	10
10426500	H-A 3 MTgv	-	11	-	-	yes	6.5 - 12	10
19512100	H-A 3 MTg M20	20	-	-	-	-	-	10
19426500	H-A 3 MTgv M20	20	-	-	-	yes	3 - 13.5	10
19512102	H-A 3 MTGV 7-13	-	-	-	-	yes	7.0 - 13.0	10

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16