


EPIC® H-B 10 TGH-RO

H-B.

가

UL50E

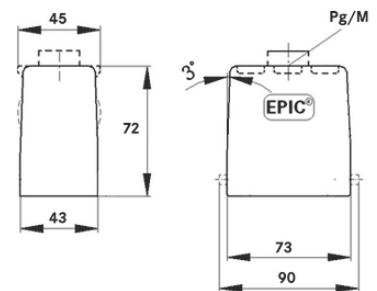

Lapp



가 가 .

가

(23.12.2023)

©2023 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

EPIC® H-B 10 TGH-RO

neck /

ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 class :

ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

:

: - ,

: -

: NBR

가:

IP 65 (latched)

NEMA 250, UL50E: 12 (latched)

VDE- :

: VDE-REG. : B437

UL- :

UL : E75770

:

-40°C to +100°C, short-term up to +125°C

가 VAT 가 가 .

(23.12.2023)

©2023 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

EPIC® H-B 10 TGH-RO

	Article description	M	PG	Neck	/ PU
H-B	: (, ,)				
70044200	H-B 10 TGH-RO 21	-	21	yes	10
70044400	H-B 10 TGH-RO 29	-	29	yes	10
79044200	H-B 10 TGH-RO M25	25	-	-	10
79044400	H-B 10 TGH-RO M32	32	-	-	10

(23.12.2023)

©2023 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16