


**EPIC® H-B 6 SGRL-LB**

H-B.

가 .2

2 가  
UL50E

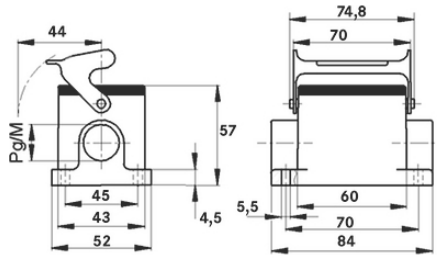

Lapp



H-B 가 . 가

(18.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16

# EPIC® H-B 6 SGRL-LB

2

ETIM 5:

ETIM 5.0 Class-ID: EC000437

ETIM 5.0 class :

ETIM 6:

ETIM 6.0 Class-ID: EC000437

ETIM 6.0 Class-Description: Housing for industrial connectors

:

: - ,

:

: NBR

가:

IP 65 (latched)

NEMA 250, UL50E: 12, 4 (latched)

VDE- :

: VDE-REG. : B437

UL- :

UL : E75770

:

-40°C to +100°C, short-term up to +125°C

가 VAT 가 가 .

(18.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16



EPIC® H-B 6 SGRL-LB

	Article description	M	PG	Packaging unit
H-B	: - (2 , )			
10006000	H-B 6 SGRL 16	-	16	10
19006000	H-B 6 SGRL M20	20	-	10
79006600	H-B 6 SGRL M25	25	-	10

(18.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16