


EPIC® MH PE 10.0mm

The mixed assembly guarantees high flexibility. For applications in machine and plant engineering, for robotics and slide-in technology.

-

(PE)

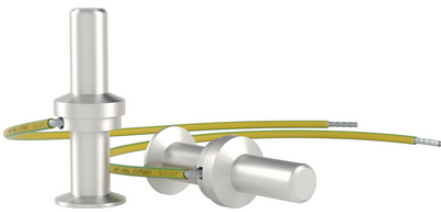

Male and female contacts with silver plating and approx. 14cm stranded wire to connect the PE Pin of the EPIC® MH Multiframe
 Klauke D 22 HD 13
 : 25, 35, 50, 70, 95mm²

/

:

: 25mm² ... 95mm²

PE

4mm²

(mm):

20

:

brass silver plated CuZn / Ag

:

500

가 VAT 가 가 .

(23.04.2024)



EPIC® MH PE 10.0mm

	Article description	Contact type	(mm ²)	PL_VERPACKUNGSEINHEIT1
EPIC® MH 10.0mm				
44423344	EPIC® MH PE SCEM AG 25sqmm D=10.0		25	1
44423345	EPIC® MH PE BCEM AG 25sqmm D=10.0		25	1
44423346	EPIC® MH PE SCEM AG 35sqmm D=10.0		35	1
44423347	EPIC® MH PE BCEM AG 35sqmm D=10.0		35	1
44423348	EPIC® MH PE SCEM AG 50sqmm D=10.0		50	1
44423349	EPIC® MH PE BCEM AG 50sqmm D=10.0		50	1
44423350	EPIC® MH PE SCEM AG 70sqmm D=10.0		70	1
44423351	EPIC® MH PE BCEM AG 70sqmm D=10.0		70	1
44423352	EPIC® MH PE SCEM AG 95sqmm D=10.0		95	1
44423353	EPIC® MH PE BCEM AG 95sqmm D=10.0		95	1

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16