


EPIC® MH Coax 2.5mm

The mixed assembly guarantees high flexibility. For applications in machine and plant engineering, for robotics and slide-in technology.

EPIC® MH Coax, 1-pole module with shielding, robust EPIC® H-BE contacts with 2.5mm diameter for the transmission of signals with EMC protection

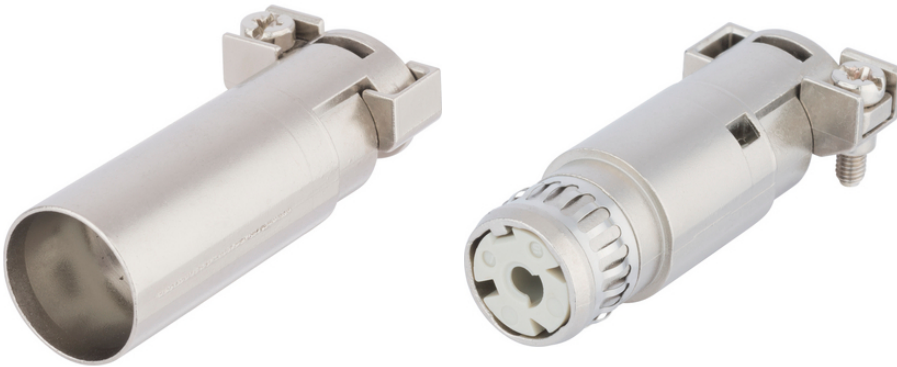

Lapp



가

Crimp connection for permanent vibration proof contacting

Railway applications

- Fire protection on railway vehicles: Test according EN 45545-2. Requirement sets R22 and R23. Hazard level HL1, HL2 and HL3

1

(14.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



EPIC® MH Coax 2.5mm

/

ETIM 5:	ETIM 5.0 Class-ID: EC002641
	ETIM 5.0 : ()
ETIM 6:	ETIM 6.0 Class-ID: EC002641
	ETIM 6.0 Class : ()
(V):	50
:	0,8 kV
(A):	16
:	3
:	UL94 V-0
/ :	1
:	500
:	UL- :
	UL : E75770
:	-40°C +125°C

가 VAT 가 가 .

(14.07.2024)



EPIC® MH Coax 2.5mm

	Article description	Contact type		Packaging unit
44423262	EPIC® MHS Coax D=2.5mm		1	10
44423263	EPIC® MHB Coax D=2.5mm		1	10

(14.07.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16