

EPIC® TB-H-BE 16

:	: 0.5 - 4.0 mm ²
(mm):	13
:	200
:	-40°C to +100°C, short-term up to +125°C

가 VAT 가 가 .



EPIC® TB-H-BE 16

	Article description	Contact type			/ PU
16-					
70315100	TB-H-BE 16 BRE			1 - 16	10
70314100	TB-H-BE 16 BLI			1 - 16	10

(23.12.2023)


©2023 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

EPIC® TB-H-BE 16

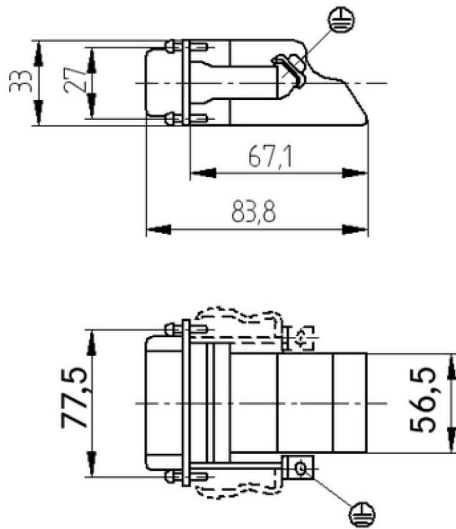

(23.12.2023)

©2023 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16