



DYMO® XTL 300 / 500



XTL 500: 54mm,

UL , UL 969 : MH48389

(24.04.2024)



DYMO® XTL 300 / 500

PC DYMO ID (www.dymo.com 가)

Kit contains 1 DYMO 500 (incl. labels VIN 54BK / WH and LAM 38x39 WH), charging adapter, USB cable, Li-Ion battery, lanyard and instruction in a hard case

ETIM 5:	ETIM 5.0 Class-ID: EC001288
:	ETIM 5.0 class :
:	: (UL224), 3: 1
:	-40 °C +60 °C

DYMO® Sanford GmbH,a Newell maid Company .

가 VAT 가 가 .

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



DYMO® XTL 300 / 500

		(mm)	Ø (mm)		Printer	m / PU
83257107	DYMO XTL KIT 500	-	-	-	-	-
83257146	DYMO XTL VIN 12BK/TR	12	-		XTL 300/500	7
83257156	DYMO XTL VIN 12BK/WH	12	-		XTL 300/500	7
83257157	DYMO XTL VIN 19BK/WH	19	-		XTL 300/500	7
83257160	DYMO XTL VIN 54BK/WH	54	-		XTL 500	7
83257170	DYMO XTL VIN 54WH/RD	54	-		XTL 500	7
83257176	DYMO XTL VIN 12BK/YE	12	-		XTL 300/500	7
83257180	DYMO XTL VIN 54BK/YE	54	-		XTL 500	7
83257214	DYMO XTL SHRINK 6-2700BK/WH	6	2.0 - 6.0		XTL 300/500	2.7
83257215	DYMO XTL SHRINK 12-2700BK/WH	12	4.0 - 12.0		XTL 300/500	2.7
83257216	DYMO XTL SHRINK 24-2700BK/WH	24	8.0 - 24.0		XTL 300/500	2.7

(24.04.2024)


©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

DYMO® XTL 300 / 500

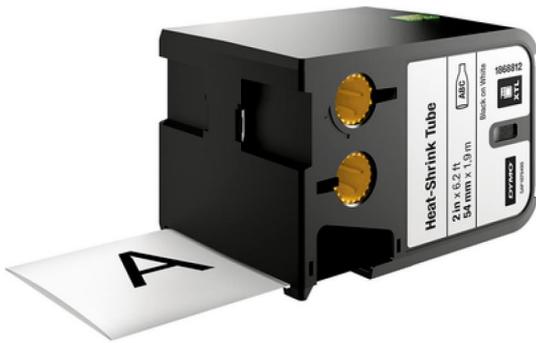

(24.04.2024)