


FLEXIMARK® Collar Snap-on

FLEXIMARK® collars

Snap-On FLEXIMARK® 가 Snap-On 2-3,5/15(: M32511)

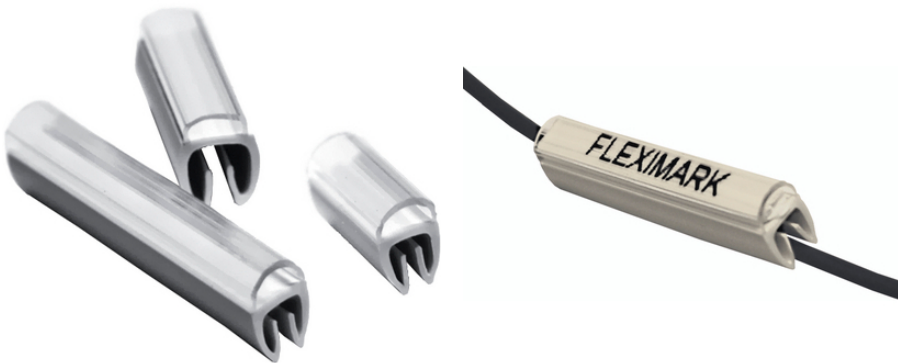

가 (, , , ...)

Extremely flame-retardant according to UL 94 V0

LMB

(collar)

ETIM 5:

ETIM 5.0 Class-ID: EC002248

ETIM 5.0 Class :

ETIM 6:

ETIM 6.0 Class-ID: EC002248

ETIM 6.0 Class :

:

Transparent

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK® Collar Snap-on

:

:

-40°C +80°C

가	VAT	가	가 .						
FLEXIMARK®) LCK 32	640	640	1	PU	

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK® Collar Snap-on

		(mm)	Ø (mm)	PU	PU
FLEXIMARK® Collar Snap-on					
83252650	FLEXIMARK® collar SnapOn 2-3.5/10 TR	10	2 - 3.5	1000	1
83252651	FLEXIMARK® collar SnapOn 2-3.5/15 TR	15	2 - 3.5	1000	1
83252695	FLEXIMARK® collar SnapOn 2-3.5/23 TR	23	2 - 3.5	500	1
83252653	FLEXIMARK® collar SnapOn 2.8-5/10 TR	10	2.8 - 5	1000	1
83252654	FLEXIMARK® collar SnapOn 2.8-5/15 TR	15	2.5 - 5	1000	1
83252656	FLEXIMARK® collar SnapOn 5-8/10 TR	10	5 - 8	500	1
83252657	FLEXIMARK® collar SnapOn 5-8/15 TR	15	5 - 8	500	1
83252660	FLEXIMARK® collar SnapOn 8-10/15 TR	15	8 - 10	500	1

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16