
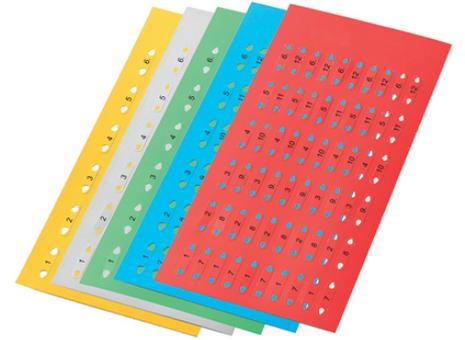
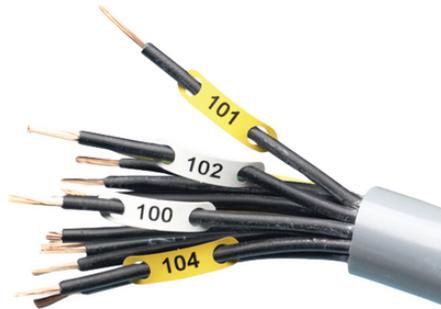


FLEXIMARK® Flexiprint LF

FLEXIMARK® Flexiprint LF

가

FLEXIMARK® 가 LF 1(M32511)

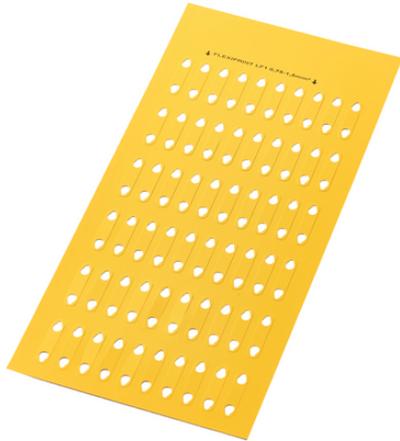

, , (, , , ...)

16 mm²

FLEXIMARK®

가

가 가
: 7

(24.04.2024)



FLEXIMARK® Flexiprint LF

1 20~60
: 80-100mm x 210mm

ETIM 5: ETIM 5.0 Class-ID: EC001288
ETIM 5.0 class :

ETIM 6: ETIM 6.0 Class-ID: EC001288
ETIM 6.0 Class :

: ,
:

: : 0.175mm

: -40°C +125°C

가 VAT 가 가 .) LCK 32 640 640 1 PU
FLEXIMARK®

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK® Flexiprint LF

			A (mm)	A (mm)	C (mm)	D (mm)	E (mm)	mm ²	PU
(10)									
83254410	FLEXIMARK® Flexiprint LF0 YE		22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	600
83254430	FLEXIMARK® Flexiprint LF1 YE		23	5.2	4.9	11.2	3.5	0.75 - 1.5	600
83254447	FLEXIMARK® Flexiprint LF1L YE		34	5.2	5	22	3.5	0.75 - 1.5	300
83254470	FLEXIMARK® Flexiprint LF1B YE		25	5.7	5.9	11.2	4.2	1.5 - 2.5	600
83254487	FLEXIMARK® Flexiprint LF1BL YE		36	5.7	6	22	4.2	1.5 - 2.5	300
83254510	FLEXIMARK® Flexiprint LF2 YE		26	7	6.5	11	5.5	2.5 - 6.0	300
83254530	FLEXIMARK® Flexiprint LF3 YE		41	11	10.5	17	8.4	6.0 - 16.0	200
83254416	FLEXIMARK® Flexiprint LF0 WH		22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	600
83254436	FLEXIMARK® Flexiprint LF1 WH		23	5.2	4.9	11.2	3.5	0.75 - 1.5	600
83254448	FLEXIMARK® Flexiprint LF1L WH		34	5.2	5	22	3.5	0.75 - 1.5	300
83254476	FLEXIMARK® Flexiprint LF1B WH		25	5.7	5.9	11.2	4.2	1.5 - 2.5	600
83254488	FLEXIMARK® Flexiprint LF1BL WH		36	5.7	6	22	4.2	1.5 - 2.5	300
83254516	FLEXIMARK® Flexiprint LF2 WH		26	7	6.5	11	5.5	2.5 - 6.0	300
83254536	FLEXIMARK® Flexiprint LF3 WH		41	11	10.5	17	8.4	6.0 - 16.0	200

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

FLEXIMARK® Flexiprint LF

			A (mm)	A (mm)	C (mm)	D (mm)	E (mm)	mm ²	PU
(75)									
83280005	FLEXIMARK® Flexiprint LF0 YE-75		22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	4500
83254420	FLEXIMARK® Flexiprint LF1 YE-75		23	5.2	4.9	11.2	3.5	0.75 - 1.5	4500
83254440	FLEXIMARK® Flexiprint LF1L YE-75		34	5.2	5	22	3.5	0.75 - 1.5	2250
83254460	FLEXIMARK® Flexiprint LF1B YE-75		25	5.7	5.9	11.2	4.2	1.5 - 2.5	4500
83254480	FLEXIMARK® Flexiprint LF1BL YE-75		36	5.7	6	22	4.2	1.5 - 2.5	2250
83254500	FLEXIMARK® Flexiprint LF2 YE-75		26	7	6.5	11	5.5	2.5 - 6.0	4500
83254520	FLEXIMARK® Flexiprint LF3 YE-75		41	11	10.5	17	8.4	6.0 - 16.0	1500
83254406	FLEXIMARK® Flexiprint LF0 WH-75		22.9	5.2	3.9	13.1	2.4	0.25 - 0.75	4500
83254426	FLEXIMARK® Flexiprint LF1 WH-75		23	5.2	4.9	11.2	3.5	0.75 - 1.5	4500
83254446	FLEXIMARK® Flexiprint LF1L WH-75		34	5.2	5	22	3.5	0.75 - 1.5	2250
83254466	FLEXIMARK® Flexiprint LF1B WH-75		25	5.7	5.9	11.2	4.2	1.5 - 2.5	4500
83254486	FLEXIMARK® Flexiprint LF1BL WH-75		36	5.7	6	22	4.2	1.5 - 2.5	2250
83254506	FLEXIMARK® Flexiprint LF2		26	7	6.5	11	5.5	2.5 - 6.0	4500

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03_16



FLEXIMARK® Flexiprint LF

			A (mm)	A (mm)	C (mm)	D (mm)	E (mm)	mm ²	PU
	WH-75								
83254526	FLEXIMARK® Flexiprint LF3 WH-75		41	11	10.5	17	8.4	6.0 - 16.0	1500

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK® Flexiprint LF



(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16