


FLEXIMARK®

PUR

FLEXIMARK® Cablelabel PUR

FLEXIMARK® PUR 60-10(: M3251010)

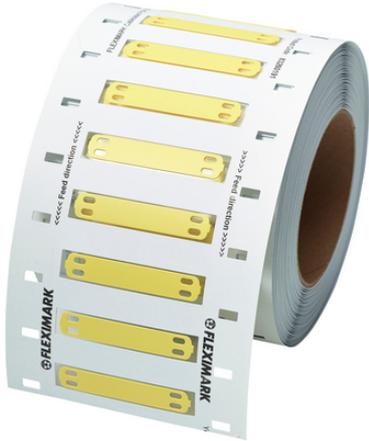

가

UV-

Flexible material allows easy installation with 1 or 2 detectable cable ties

(: 가 ,) 가

(24.04.2024)



FLEXIMARK®

PUR

가

Extremely flame-retardant according to
UL 94 V0
MIL 81531 MIL-STD-202G

Easy to print via FLEXIMARK®
software Flexisoft and FLEXIMARK®

thermal transfer printer SQUIX, EOS5 or EOS2
: FLEXIMARK® FTI-Y 110-360 BK (. 83260200)

: FLEXIMARK® PUR FCC

ETIM 5:

ETIM 5.0 Class-ID: EC001530

ETIM 5.0 class :

ETIM 6:

ETIM 6.0 Class-ID: EC001530

ETIM 6.0 Class :

:

Standard colour: Yellow, white

: , , , , ,

:

PUR

:

-50°C bis +100°C
+125°C

가 VAT 가 가 .
FLEXIMARK®

.) LCK 32 640 640

1 PU

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK®

PUR

			x (mm)	PU	PU
(1)					
83280275	FLEXIMARK® Cablelabel PUR 20x30 YE Diamond		30.0 x 20.0	1000	1
83280276	FLEXIMARK® Cablelabel PUR 20x30 WH Diamond		30.0 x 20.0	1000	1
(1)					
83280277	FLEXIMARK® Cablelabel PUR 55x12 YE		12.0 x 55.0	1000	1
83280278	FLEXIMARK® Cablelabel PUR 55x12 WH		12.0 x 55.0	1000	1
(2)					
83280279	FLEXIMARK® Cablelabel PUR 35x10 YE		10.0 x 35.0	1000	1
83260191	FLEXIMARK® Cablelabel PUR 60x10 YE		10.0 x 60.0	1000	1
83260192	FLEXIMARK® Cablelabel PUR 75x15 YE		15.0 x 75.0	1000	1
83260193	FLEXIMARK® Cablelabel PUR 75x25 YE		25.0 x 75.0	500	1
83255321	FLEXIMARK® Cablelabel PUR 100x60 YE		60.0 x 100.0	250	1
83280280	FLEXIMARK® Cablelabel PUR 35x10 WH		10.0 x 35.0	1000	1
83260194	FLEXIMARK® Cablelabel PUR 60x10 WH		10.0 x 60.0	1000	1
83260195	FLEXIMARK® Cablelabel PUR 75x15 WH		15.0 x 75.0	1000	1
83260196	FLEXIMARK® Cablelabel PUR 75x25 WH		25.0 x 75.0	500	1
83255322	FLEXIMARK® Cablelabel PUR 100x60 WH		60.0 x 100.0	250	1
83280260	FLEXIMARK® Cablelabel PUR 60x10 RD		10.0 x 60.0	1000	1
83280261	FLEXIMARK® Cablelabel PUR 75x15 RD		15.0 x 75.0	1000	1
83280262	FLEXIMARK® Cablelabel PUR 75x25 RD		25.0 x 75.0	500	1
83280263	FLEXIMARK® Cablelabel PUR 60x10 OG		10.0 x 60.0	1000	1
83280264	FLEXIMARK® Cablelabel		15.0 x 75.0	1000	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK®

PUR

		x (mm)	PU	PU
	PUR 75x15 OG			
83280265	FLEXIMARK® Cablelabel PUR 75x25 OG	25.0 x 75.0	500	1
83280266	FLEXIMARK® Cablelabel PUR 60x10 BU	10.0 x 60.0	1000	1
83280267	FLEXIMARK® Cablelabel PUR 75x15 BU	15.0 x 75.0	1000	1
83280268	FLEXIMARK® Cablelabel PUR 75x25 BU	25.0 x 75.0	500	1
83280269	FLEXIMARK® Cablelabel PUR 60x10 BK	10.0 x 60.0	1000	1
83280270	FLEXIMARK® Cablelabel PUR 75x15 BK	15.0 x 75.0	1000	1
83280271	FLEXIMARK® Cablelabel PUR 75x25 BK	25.0 x 75.0	500	1
83280272	FLEXIMARK® Cablelabel PUR 60x10 GN	10.0 x 60.0	1000	1
83280273	FLEXIMARK® Cablelabel PUR 75x15 GN	15.0 x 75.0	1000	1
83280274	FLEXIMARK® Cablelabel PUR 75x25 GN	25.0 x 75.0	500	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK®

PUR



(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16