

FLEXIMARK® Flexiprint TF



FLEXIMARK® Flexiprint TF

가

FLEXIMARK®

TF 1(

M32511)

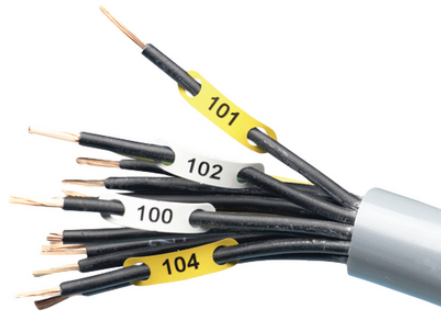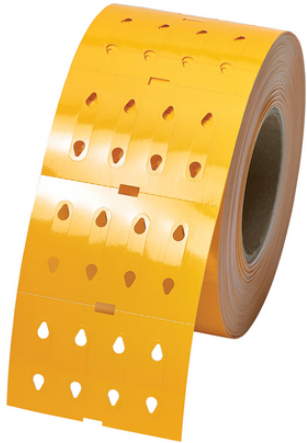

, , (, , , ...)

16 mm²

Easy to print via FLEXIMARK® software Flexisoft and FLEXIMARK®

thermal transfer printer SQUIX, EOS5 or EOS2
 : R71 110-360 BK (83259609)
 : 7

(24.04.2024)



FLEXIMARK® Flexiprint TF

ETIM 5:

ETIM 5.0 Class-ID: EC001288

ETIM 5.0 class :

ETIM 6:

ETIM 6.0 Class-ID: EC001288

ETIM 6.0 Class :

:

Yellow

Also available in green, blue and red

:

: 0.175mm

:

-40°C +125°C

가	VAT	가	가 .) LCK 32	640	640	1	PU
FLEXIMARK®								

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK® Flexiprint TF

			mm ²	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	PU	PU
83255011	FLEXIMARK® Flexiprint TF0 WH600		0.25 - 0.75	22.9	5.2	3.9	13.1	2.4	600	1
83255012	FLEXIMARK® Flexiprint TF1 WH600		0.75 - 1.5	23	5.2	4.9	11.2	3.5	600	1
83255013	FLEXIMARK® Flexiprint TF1B WH600		1.5 - 2.5	25	5.7	5.9	11.2	4.2	600	1
83255014	FLEXIMARK® Flexiprint TF2 WH600		2.5 - 6.0	26	7	6.5	11	5.5	600	1
83255015	FLEXIMARK® Flexiprint TF3 WH600		6.0 - 16.0	41	11	10.5	17	8.4	200	1
83254372	FLEXIMARK® Flexiprint TF0 YE		0.25 - 0.75	22.9	5.2	3.9	13.1	2.4	2000	1
83254378	FLEXIMARK® Flexiprint TF1 YE		0.75 - 1.5	23	5.2	4.9	11.2	3.5	2000	1
83254354	FLEXIMARK® Flexiprint TF1L YE		0.75 - 1.5	34	5.2	5	22	3.5	2000	1
83254374	FLEXIMARK® Flexiprint TF1B YE		1.5 - 2.5	25	5.7	5.9	11.2	4.2	2000	1
83254359	FLEXIMARK® Flexiprint TF1BL YE		1.5 - 2.5	36	5.7	6	22	4.2	2000	1
83254375	FLEXIMARK® Flexiprint TF2 YE		2.5 - 6.0	26	7	6.5	11	5.5	2000	1
83254376	FLEXIMARK® Flexiprint TF3 YE		6.0 - 16.0	41	11	10.5	17	8.4	1000	1

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03_16



FLEXIMARK® Flexiprint TF

			mm ²	A (mm)	B (mm)	C (mm)	D (mm)	E (mm)	PU	PU
83254365	FLEXIMARK® Flexiprint TF0 WH		0.25 - 0.75	22.9	5.2	3.9	13.1	2.4	2000	1
83254366	FLEXIMARK® Flexiprint TF1 WH		0.75 - 1.5	23	5.2	4.9	11.2	3.5	2000	1
83254355	FLEXIMARK® Flexiprint TF1L YE		0.75 - 1.5	34	5.2	5	22	3.5	2000	1
83254367	FLEXIMARK® Flexiprint TF1B WH		1.5 - 2.5	25	5.7	5.9	11.2	4.2	2000	1
83254360	FLEXIMARK® Flexiprint TF1BL WH		1.5 - 2.5	36	5.7	6	22	4.2	2000	1
83254368	FLEXIMARK® Flexiprint TF2 WH		2.5 - 6.0	26	7	6.5	11	5.5	2000	1
83254369	FLEXIMARK® Flexiprint TF3 WH		6.0 - 16.0	41	11	10.5	17	8.4	1000	1

(24.04.2024)


©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

FLEXIMARK® Flexiprint TF

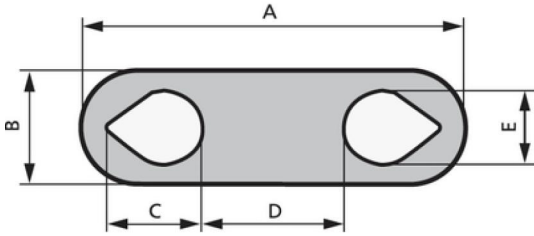

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16