


FLEXIMARK® Shrink mark

FLEXIMARK® Flat

가

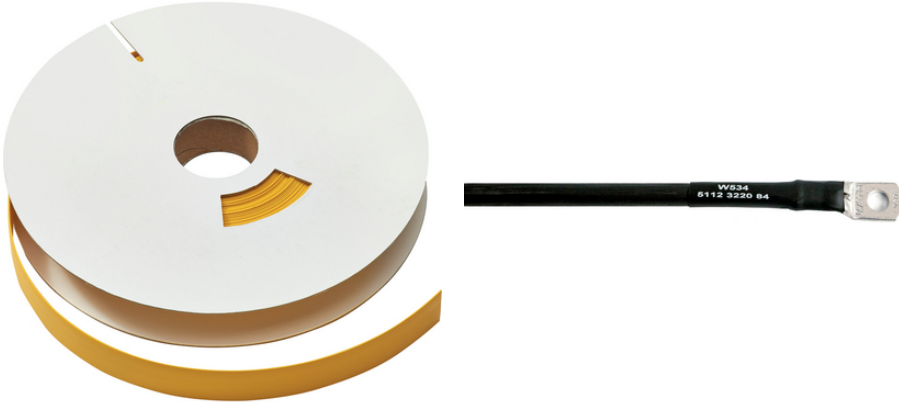

UL 224

Easy to print via FLEXIMARK®
software Flexisoft and FLEXIMARK®

thermal transfer printer SQUIX, EOS5 or EOS2

- : FTI-X 60-300 BK (article no. 83260206),
- : FTI-X 55-300 WH (article no. 83260260)

SQUIX 가 EOS5
: FLEXIMARK® FCC

가

(12.05.2024)



FLEXIMARK® Shrink mark

ETIM 5:

ETIM 5.0 Class-ID: EC001288

ETIM 5.0 Class-Description: Schrumpfschlauch

ETIM 6:

ETIM 6.0 Class :

:

,

:

: 3:1

:

-55°C +135°C

가	VAT	가	가	.) LCK 32	640	640	1	PU
FLEXIMARK®									

(12.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16



FLEXIMARK® Shrink mark

			(mm)	PU (m)	PU
83251670	FLEXIMARK® Shrinking tube 3/1 BK		1.0 - 3.0	30	1
83251671	FLEXIMARK® Shrinking tube 6/2 BK		2.0 - 6.0	25	1
83251672	FLEXIMARK® Shrinking tube 9/3 BK		3.0 - 9.0	20	1
83251673	FLEXIMARK® Shrinking tube 12/4 BK		4.0 - 12.0	20	1
83251674	FLEXIMARK® Shrinking tube 18/6 BK		6.0 - 18.0	20	1
83251680	FLEXIMARK® Shrinking tube 3/1 YE		1.0 - 3.0	30	1
83251681	FLEXIMARK® Shrinking tube 6/2 YE		2.0 - 6.0	25	1
83251682	FLEXIMARK® Shrinking tube 9/3 YE		3.0 - 9.0	20	1
83251683	FLEXIMARK® Shrinking tube 12/4 YE		4.0 - 12.0	20	1
83251684	FLEXIMARK® Shrinking tube 18/6 YE		6.0 - 18.0	20	1
83251690	FLEXIMARK® Shrinking tube 3/1 WH		1.0 - 3.0	30	1
83251691	FLEXIMARK® Shrinking tube 6/2 WH		2.0 - 6.0	25	1
83251692	FLEXIMARK® Shrinking tube 9/3 WH		3.0 - 9.0	20	1
83251693	FLEXIMARK® Shrinking tube 12/4 WH		4.0 - 12.0	20	1
83251694	FLEXIMARK® Shrinking tube 18/6 WH		6.0 - 18.0	20	1

(12.05.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16