


FLEXIMARK® TA

FLEXIMARK® (, (

FLEXIMARK® (M32511)

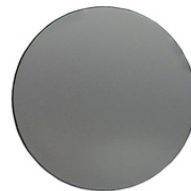

UV-

Easy to print via FLEXIMARK®
software Flexisoft and FLEXIMARK®

thermal transfer printer SQUIX, EOS5 or EOS2
Recommended ribbon: FTI-Y 60-360 BK (article no. 83260201)

(21.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

FLEXIMARK® TA

ETIM 5:

ETIM 5.0 Class-ID: EC001288

ETIM 5.0 class :

ETIM 6:

ETIM 6.0 Class-ID: EC001288

ETIM 6.0 Class :

$$\vdots$$
$$\vdots$$

•

•

-40 °C +90 °C

가 VAT 가 가 .
FLEXIMARK®

.) LCK 32

640

640

1

PU



FLEXIMARK® TA

			(mm)	Length (mm)	PU	PU
83255338	FLEXIMARK® TA foam 13-7 SR		7	13	1000	1
83255339	FLEXIMARK® TA foam 22-22 SR		22	22	1000	1
83255340	FLEXIMARK® TA foam 27-8 SR		8	27	1000	1
83260166	FLEXIMARK® TA foam 27-12.5 SR		12.5	27	1000	1
83260167	FLEXIMARK® TA foam 27-15 SR		15	27	1000	1
83260168	FLEXIMARK® TA foam 27-18 SR		18	27	1000	1
83255341	FLEXIMARK® TA foam 27-27 SR		27	27	1000	1
83260170	FLEXIMARK® TA foam 30-40 SR		40	30	1000	1
83260171	FLEXIMARK® TA foam 35-15 SR		15	35	1000	1
83260172	FLEXIMARK® TA foam 35-18 SR		18	35	1000	1
83260173	FLEXIMARK® TA foam 45-15 SR		15	45	1000	1
83255342	FLEXIMARK® TA foam 45-25 SR		25	45	1000	1
83255343	FLEXIMARK® TA foam 48-19 SR		19	48	1000	1
83260176	FLEXIMARK® TA foam 50-15 SR		15	50	1000	1
83260177	FLEXIMARK® TA foam 50-25 SR		25	50	750	1
83260179	FLEXIMARK® TA foam 60-30 SR		30	60	500	1
83260180	FLEXIMARK® TA foam 70-18 SR		18	70	1000	1
83255344	FLEXIMARK® TA foam 90-15 SR		15	90	250	1
83260182	FLEXIMARK® TA foam 90-30 SR		30	90	250	1
83260183	FLEXIMARK® TA foam 90-45 SR		45	90	250	1

(21.02.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02_03.16

FLEXIMARK® TA

			(mm)	Length (mm)	PU	PU
83260185	FLEXIMARK® TA foam 100-30 SR		30	100	250	1
83260186	FLEXIMARK® TA foam 100-50 SR		50	100	250	1
83255345	FLEXIMARK® TA foam 100-70 SR		70	100	250	1
83260188	FLEXIMARK® TA foam 105-140 SR		140	105	250	1
83260164	FLEXIMARK® TA foam 27-8 WH		8	27	1000	1
83260169	FLEXIMARK® TA foam 27-18 WH		18	27	1000	1
83260165	FLEXIMARK® TA foam 27-12.5 WH		12.5	27	1000	1
83260174	FLEXIMARK® TA foam 45-15 WH		15	45	1000	1
83260175	FLEXIMARK® TA foam 48-19 WH		19	48	1000	1
83260178	FLEXIMARK® TA foam 60-30 WH		30	60	500	1
83260181	FLEXIMARK® TA foam 90-30 WH		30	90	250	1
83260184	FLEXIMARK® TA foam 90-45 WH		45	90	250	1
83260187	FLEXIMARK® TA foam 100-50 WH		50	100	250	1
Round cut-out						
83260189	FLEXIMARK® TA foam 40-30 Ø 24mm SR		30	40	1000	1
83260190	FLEXIMARK® TA foam 40-30 Ø 24mm WH		30	40	1000	1