


# HITRONIC® HVN-

(Ducts)

HITRONIC® HVN-

A-DQ(ZN)2Y

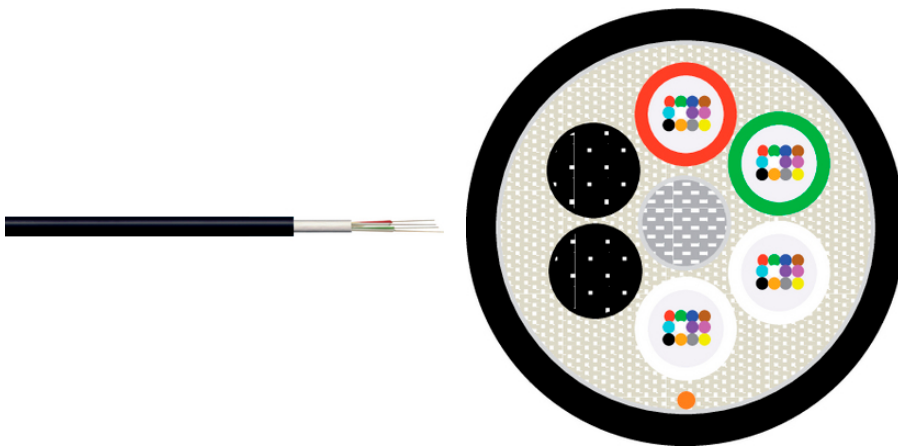

( )

, FTTH

WAN

:

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16

# HITRONIC® HVN-

가 144  
( 가 12 12 )

UV-

12  
GRP

PE  
: (RAL 9005)

ETIM 5:

ETIM 5.0 Class-ID: EC000034  
ETIM 5.0 Class-Description:

ETIM 6:

ETIM 6.0 Class-ID: EC000034  
ETIM 6.0 Class : LWL

Fibre type:

GOF - Glass Optical Fibre

::

E9/125 OS2

:

A-DQ(ZN)2Y

가 :

: 15 x

: 20 x

:

: -40°C ~ +70°C

가 VAT 가 가 . ( . ) 가 .



HITRONIC® HVN-

		Fibre type	Number of fibres	(mm)	(kg/km)
E 9 OS2					
26609912	HITRONIC® HVN-Mini500 1x12E 9/125 OS2	9/125 OS2	12	5.8	30
26609924	HITRONIC® HVN-Mini500 2x12E 9/125 OS2	9/125 OS2	24	5.8	30
26609948	HITRONIC® HVN-Mini500 4x12E 9/125 OS2	9/125 OS2	48	5.8	33
26609972	HITRONIC® HVN-Mini500 6x12E 9/125 OS2	9/125 OS2	72	5.8	33
26609996	HITRONIC® HVN-Mini1200 8x12E 9/125 OS2	9/125 OS2	96	7.2	52
26609944	HITRONIC® HVN-Mini1000 12x12E 9/125	9/125 OS2	144	8	80

(24.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16