


# HITRONIC® HQA

가 ; ADSS

HITRONIC® HQA ADSS ( ), ,

A-DQ(ZN)2Y

ADSS - All Dielectric Self Supporting

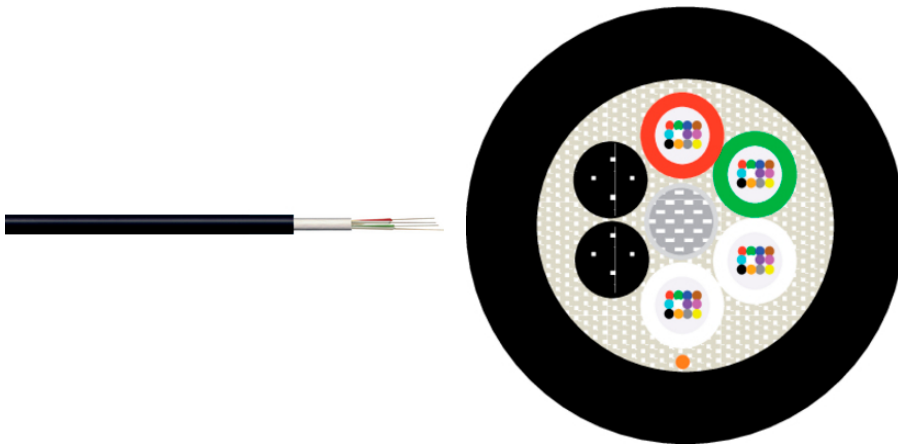

, ,  
( )

(23.04.2024)

# HITRONIC® HQA

가 96  
( )  
90m

GRP 8  
(Aramid Yarns)

PE : (RAL 9005)

ETIM 5: ETIM 5.0 Class-ID: EC000034  
ETIM 5.0 Class-Description:  
ETIM 6: ETIM 6.0 Class-ID: EC000034  
ETIM 6.0 Class : LWL  
: 1 : 250µm  
:

Fibre type: GOF - Glass Optical Fibre  
:: A-DQ(ZN)2Y - ADSS  
: All-Dielectric Self-Supporting  
:  
: :  
가 : : 15 x  
: 20 x  
가 : MAT: 2000 N  
EDS: 800 N  
: : -40°C ~ +70°C  
: -30 °C ~ +70 °C

가 VAT 가 가 . 가 가 . ( . ) 가 .  
가



HITRONIC® HQA

		Fibre type	Number of fibres	(mm)	(kg/km)
E 9 OS2					
26640912	HITRONIC® HQA800 6x2E 9/125 OS2	9/125 OS2	12	9.7	73
26640924	HITRONIC® HQA800 6x4E 9/125 OS2	9/125 OS2	24	9.7	73
26640948	HITRONIC® HQA800 6x8E 9/125 OS2	9/125 OS2	48	10.9	92
26640996	HITRONIC® HQA800 8x12E 9/125 OS2	9/125 OS2	96	12.4	121

(23.04.2024)

©2024 Lapp Group - all rights reserved.

<http://lappkorea.lappgroup.com>

data sheet

PN 0456 / 02\_03.16